


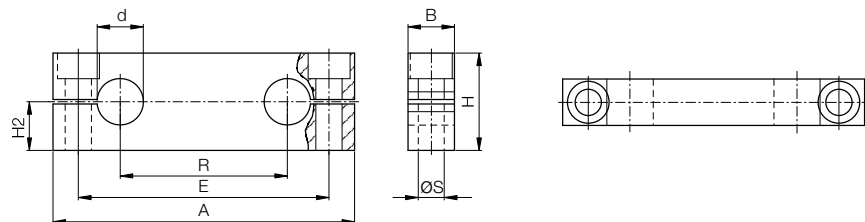

Order key

Type Size

T A F - 08Shaft end support
Fixed
Inner ØMaterial: Aluminium
Mounting hole


Dimensions [mm]

Part No.	d	A	B	H	H2 ±0.015	Ø S	E	R	Weight [g]
TAF-08	8	65	12	23	12.5	5.5	52	32	40
TAF-10	10	70	12	25	14.0	5.5	55	24	45
TAF-12	12	85	14	32	18.0	6.6	70	42	90
TAF-16	16	100	18	36	20.0	9.0	82	54	140
TAF-20	20	130	20	46	25.0	11.0	108	72	250
TAF-25	25	160	25	56	30.0	13.5	132	88	470
TAF-30	30	180	25	64	35.0	13.5	150	96	620
TAF-40	40	230	30	80	44.0	17.5	190	122	1,150



Order example:

TAF-12 for a fixed shaft end support with inner Ø 12 mm

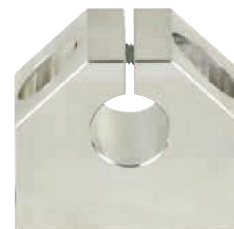


Order key

Type Size

W A - 08Shaft end block
Standard version
Inner Ø

Material: Aluminium

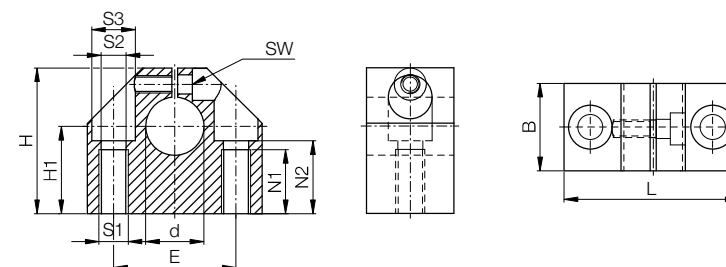

Dimensions [mm]

Part No.	d	B	H	H1 ±0.02	L	S1	S2	S3	E ±0.1	N1	N2	SW	Weight [g]
WA-08	8	18	28	15	32	M4	3.3	6	22	9	13.0	2.5	40
WA-12	12	20	35	20	43	M6	5.2	10	30	13	16.5	3.0	100
WA-16	16	24	42	25	53	M8	6.8	11	38	18	21.0	4.0	150
WA-20	20	30	50	30	60	M10	8.6	15	42	22	25.0	5.0	230
WA-25	25	38	60	35	78	M12	10.3	18	56	26	30.0	6.0	410
WA-30	30	40	70	40	87	M12	10.3	18	64	26	34.0	6.0	530
WA-40	40	48	90	50	108	M16	14.25	20	82	34	44.0	8.0	990
WA-50	50	58	105	60	132	M20	17.5	26	100	43	49.0	10.0	1,250
WA-60	60	74	130	75	164	M27	22	33	124	43	59.0	10.0	2,950



Order example:

WA-08 for a shaft block, standard design with inner Ø 8 mm