 



Traverse, fest

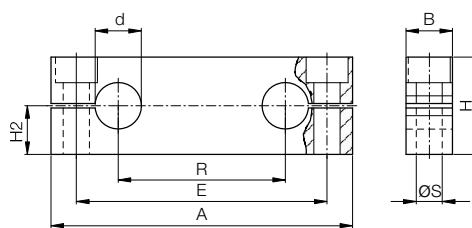

Bestellschlüssel

Typ Größe

T A F - 08Traverse
fest
Innen-ØMaterial: Aluminium
Durchgangsbohrung in Traverse

Abmessungen [mm]

Art.-Nr.	d	A	B	H	H2 ±0,015	ø S	E	R	Gewicht [g]
TAF-08	8	65	12	23	12,5	5,5	52	32	40
TAF-10	10	70	12	25	14,0	5,5	55	24	45
TAF-12	12	85	14	32	18,0	6,6	70	42	90
TAF-16	16	100	18	36	20,0	9,0	82	54	140
TAF-20	20	130	20	46	25,0	11,0	108	72	250
TAF-25	25	160	25	56	30,0	13,5	132	88	470
TAF-30	30	180	25	64	35,0	13,5	150	96	620
TAF-40	40	230	30	80	44,0	17,5	190	122	1.150

Bestellbeispiel:

TAF-12 für eine feste Traverse mit Innen-Ø 12 mm

Wellenbock, normale Bauform





Bestellschlüssel

Typ Größe

W A - 08Wellenbock
Standard-Bauform
Innen-Ø

Material: Aluminium

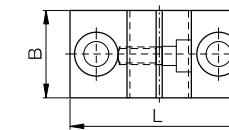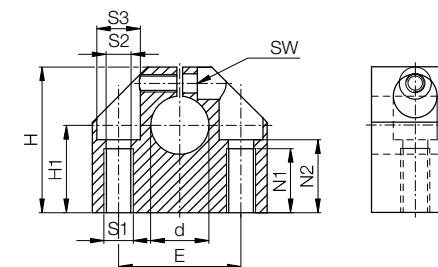

Abmessungen [mm]

Art.-Nr.	d	B	H	H1 ±0,02	L	S1	S2	S3	E ±0,1	N1	N2	SW	Gewicht [g]
WA-08	8	18	28	15	32	M4	3,3	6	22	9	13,0	2,5	40
WA-12	12	20	35	20	43	M6	5,2	10	30	13	16,5	3,0	100
WA-16	16	24	42	25	53	M8	6,8	11	38	18	21,0	4,0	150
WA-20	20	30	50	30	60	M10	8,6	15	42	22	25,0	5,0	230
WA-25	25	38	60	35	78	M12	10,3	18	56	26	30,0	6,0	410
WA-30	30	40	70	40	87	M12	10,3	18	64	26	34,0	6,0	530
WA-40	40	48	90	50	108	M16	14,25	20	82	34	44,0	8,0	990
WA-50	50	58	105	60	132	M20	17,5	26	100	43	49,0	10,0	1.250
WA-60	60	74	130	75	164	M27	22	33	124	43	59,0	10,0	2.950

Bestellbeispiel:

WA-08 für einen Wellenbock, Standard-Bauform mit Innen-Ø 8 mm