


For new constructions:
Series "E4 light"
15050/15150/R19850 ▶ page 7.150

Series 150 · 151 · R198 "E4/light"

 


igus® E-ChainSystems®

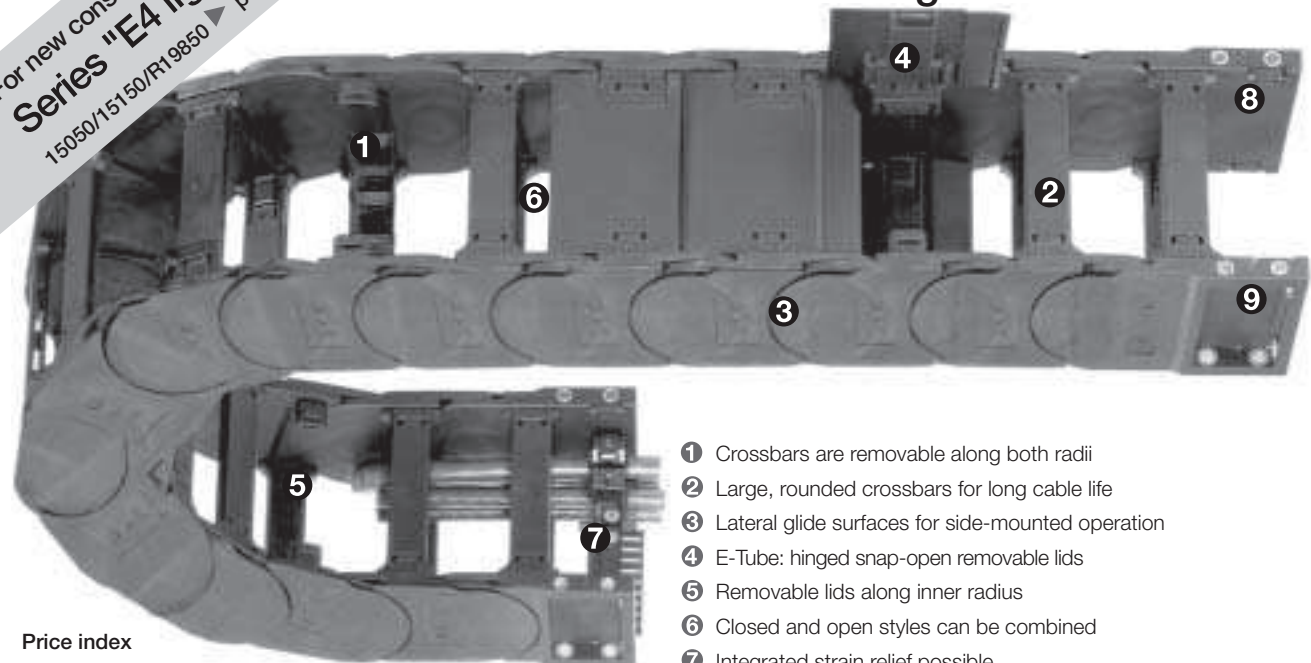


- ❶ Crossbars are removable along both radii
- ❷ Large, rounded crossbars for long cable life
- ❸ Lateral glide surfaces for side-mounted operation
- ❹ E-Tube: hinged snap-open removable lids
- ❺ Removable lids along inner radius
- ❻ Closed and open styles can be combined
- ❼ Integrated strain relief possible
- ❽ Mounting brackets available both locking and pivoting
- ❾ KMA mounting brackets with attachment points on all sides

Price index




Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222

igus® GmbH
51147 Cologne

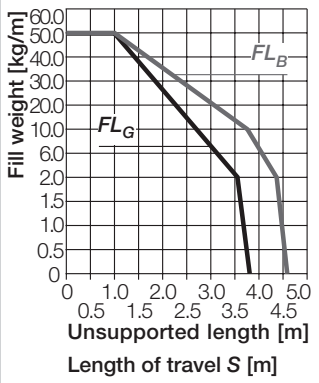


Unsupported length
 FL_G = with straight upper run
 FL_B = with permitted sag

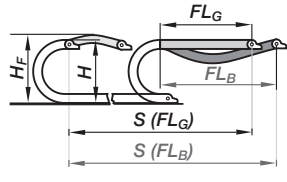


Series 150 crossbars every link



Series 151 crossbars every 2nd link

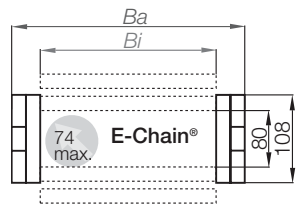

Series R198 fully enclosed E-Tube

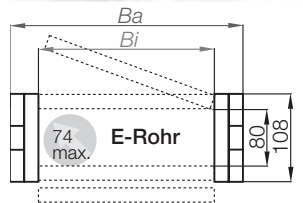

Part No.	Bi [mm]	Ba [mm]	R [mm] Bending Radii	
150/151.05.0	50	80	150** 200 250
150/151/198.07.0*	75	105	300 350 400
150/151/198.10.0	100	130	500
150/151.11.0	112	143	
150/151/198.12.0	125	155	
150/151.13.0	137	168	
150/151/198.15.0	150	180	
150/151.16.0	162	193	
150/151.17.0	175	205	
150/151.18.0	187	218	
150/151/198.20.0	200	230	
150/151.21.0	212	243	
150/151.22.0	225	255	
150/151.23.0	237	268	
150/151/198.25.0	250	280	
150/151.26.0	262	293	
150/151/198.27.0	275	305	
150/151.28.0	287	318	
150/151/198.30.0	300	330	
150/151.31.0	312	343	
150/151.32.0	325	355	
150/151.33.0	337	368	
150/151/198.35.0	350	380	
150/151.36.0	362	393	
150/151.37.0	375	405	
150/151.38.0	387	418	
150/151/198.40.0	400	430	
150/151.41.0	412	443	
150/151.42.0	425	455	
150/151.43.0	437	468	
150/151.45.0	450	480	
150/151/198.46.0	462	493	
150/151.47.0	475	505	
150/151.48.0	487	518	
150/151.50.0	500	530	
150/151.51.0	512	543	
150/151.52.0	525	555	
150/151.53.0	537	568	
150/151.55.0	550	580	
150/151.60.0	600	630	

Radii for all widths!

* Removable lid only, no hinged option
** Not available for R198

Part No. structure

150. 30. 300. 0

- Color black
- Bending radius
- Width
- Series

Order example 5,0 m complete E-Chain®
(indicate chain-lengths or number of links)

5,0 m (55 links) **Series 150.30.300.0**

+ 2 separators **511** assembled each 2nd link

+ 1 set mounting brackets with C-profile **1500.15.12.B.C**

Supplement Part No. with required radius. Example: 150.30.**300**.0
Bending radii listed above can be combined with every chain width!