





### Steel mounting bracket - locking

- Locked connections
- One part for all chain widths
- Electrically conductive
- Bolted connection outside of chain cross-section possible


Moving end with bore  
(outer link) 14000...1

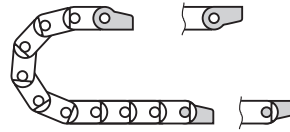

 14000...2 Fixed end  
with pin (inner link)



Possible installation conditions -  
Further installation angles ► installation sketch

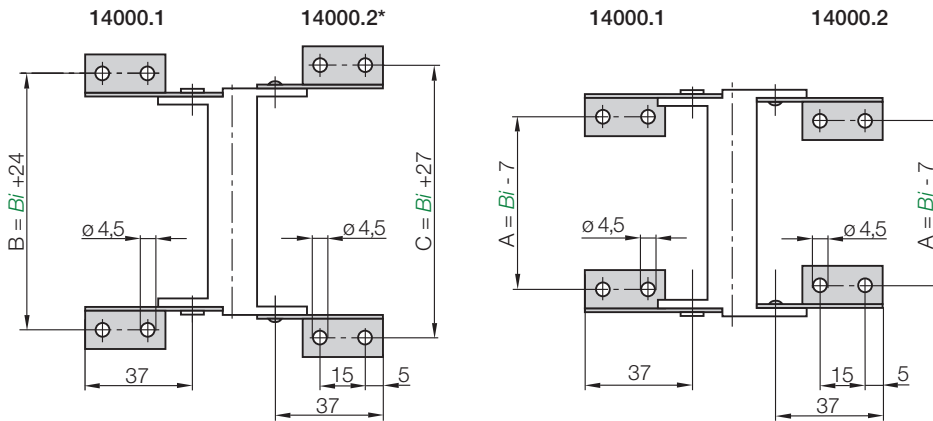

### Dimensions and order configurations

\*pivoting with no stop, (360°).  
Screw-on area of the mounting brackets can be on the interior or exterior.

For E-Chain®	Part No. full set	Dim. A [mm]	Dim. B [mm]	Dim. C [mm]
1400 - 1500.015 ►	14000. 12	8	39	42
1400 - 1500.020 ►	14000. 12	13	44	47
1400 - 1500.025 ►	14000. 12	18	49	52
1400 - 1500.038 ►	14000. 12	31	62	65
1400 - 1500.050 ►	14000. 12	43	74	77
1400 - 1500.068 ►	14000. 12	61	92	95
1400 - 1500.080 ►	14000. 12	73	104	107
1400 - 1500.100 ►	14000. 12	93	124	127
1400 - 1500.125 ►	14000. 12	118	149	152

14000. 12 Full set, 4 parts  
2 with pin / 2 with bore

#### Single-part order:

- 14000. 1 Mounting bracket with bore, 1 part left / right
- 14000. 2 Mounting bracket with pin, 1 part left / right

Phone +49- (0) 22 03-96 49-800  
Fax +49- (0) 22 03-96 49-222

