

Standard-length from stock 2,000 mm



For the following igus® series

E2/000

- 1500
- 2500
- 2700

Components - guidefast guide trough

- ① Trough profile, 2 m section
- ② Glide bar, polymer, 2 m section, optional
- ③ Clip connector, Part No. 908.467
(electrically conductive clip: 911.301.CD)

Components - trough bracket


- Ⓐ Version 01 - short trough bracket
- Ⓑ Version 02 - long trough bracket
- Ⓒ Clamping blocks, Part No. G9.2.10

Ba = e-chain® outer width

Bi = e-chain® inner width

ha = e-chain® outer height

B_{Ri} = Trough inner width

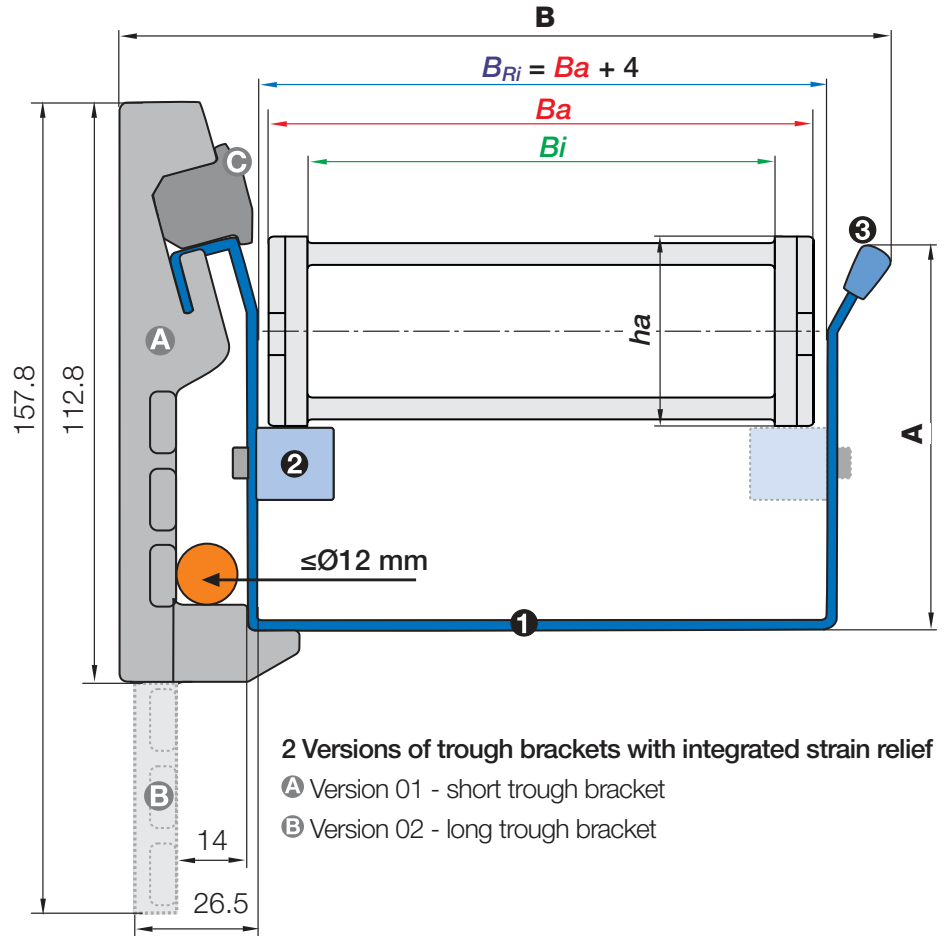

2 Versions of trough brackets with integrated strain relief

- Ⓐ Version 01 - short trough bracket
- Ⓑ Version 02 - long trough bracket



guidefast guide trough without glide bar, short trough bracket, standard-length from stock 2,000 mm



guidefast guide trough with glide bar, short trough bracket, standard-length from stock 2,000 mm