 





**Polymer, one-piece**

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled
- Inner and outer attachment possible

Moving end with bore  
(outer link) 0450...1(PZ)

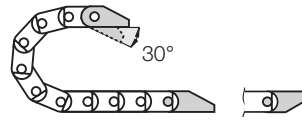



0450...2(PZ) Fixed end  
with pin (inner link)

Possible installation conditions for assembled mounting brackets ▶ Order example "preassembled" below

0450...1(PZ)  
Moving end

0450...2(PZ)  
Fixed end

**Dimensions and order configurations**

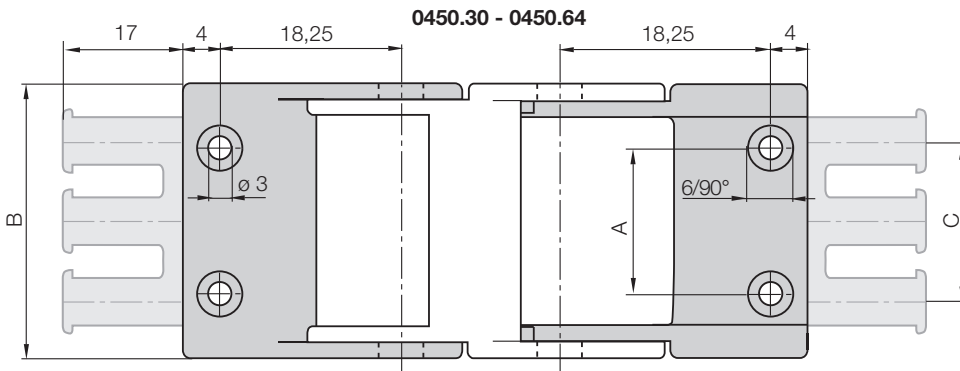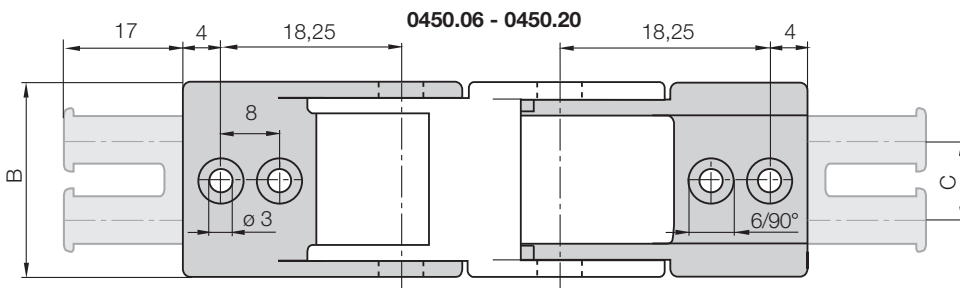


For E-Chain®	Part No. full set tiwrap plate	Part No. full set zahl tiwrap plate	Number of teeth	Dim. A [mm]	Dim. B [mm]	Dim. C [mm]
045.06. ▶	0450.06. 12 PZ	0450.06. 12	1	-	12	-
045.10. ▶	0450.10. 12 PZ	0450.10. 12	1	-	16	-
045.16. ▶	0450.16. 12 PZ	0450.16. 12	2	-	22	10
045.20. ▶	0450.20. 12 PZ	0450.20. 12	2	-	26	10
045.30. ▶	0450.30. 12 PZ	0450.30. 12	3	22	36	20
045.64. ▶	0450.64. 12 PZ	0450.64. 12	6	56	70	50

For the **preassembled** mode please add the index 0450.20. 12 PZ A1

The mounting brackets are available upon request. Time of delivery approx. 6-8 weeks after order.

**Part No. structure**

0450. 10. 12 PZ A1

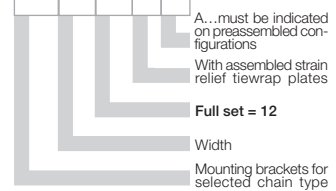

**Full set, for both ends:**

0450. 10. 12 PZ +tiwrap plate

**Single-part order:**

0450. 10. 1 PZ +tiwrap plate

Mounting bracket **with bore**

0450. 10. 2 PZ +tiwrap plate

Mounting bracket **with pin**

Phone +49- (0) 22 03-96 49-800  
Fax +49- (0) 22 03-96 49-222

