


Part No. structure

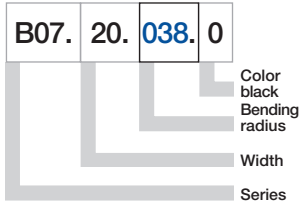

Series B07 - snap-open along inner radius

Part No.	<i>Bi</i> [mm]	<i>Ba</i> [mm]	<i>R</i> [mm]	Bending Radii			Weight [kg/m]
B07.16.□.0	16	22,5	018	028	038	≈ 0,16	
B07.20.□.0	20	27	018	028	038	≈ 0,17	
B07.30.□.0	30	37	018	028	038	≈ 0,20	
B07.40.□.0	40	47	018	028	038	≈ 0,23	

Supplement part no. with required radius (*R*) Example: B07.20.038.0

0 = standard color, other colors ► page 1.39 · Pitch = 20 mm/link - Links/m = 50

