





**Polymer, one-piece**

- One-piece mounting bracket
- Corrosion-resistant
- Available preassembled
- Inner and outer attachment possible
- Available with or without strain relief tiewrap plates

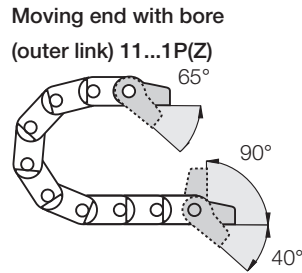


11...2P(Z) Fixed end with pin (inner link)

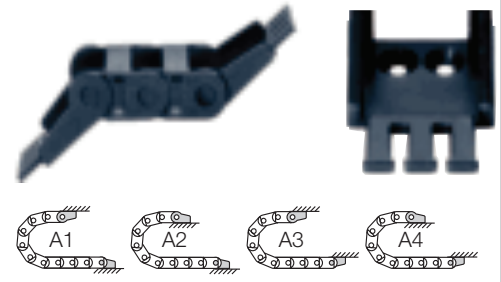

Possible installation conditions for assembled mounting brackets ► Order example "preassembled" below

11...1P(Z)  
Moving end


11...2P(Z)  
Fixed end

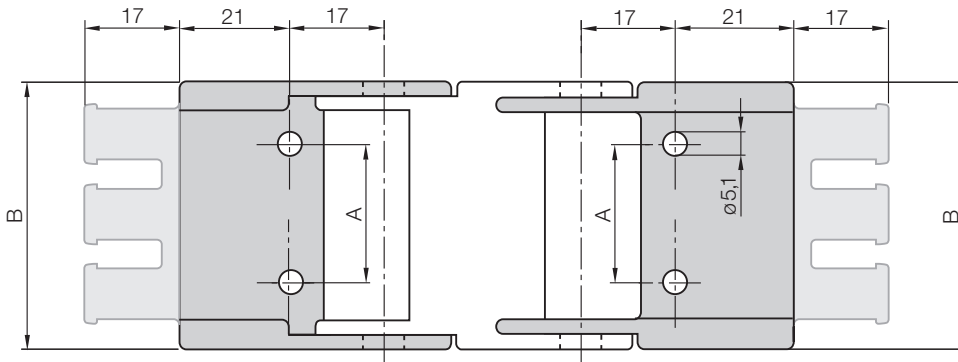

**Dimensions and order configurations**

Strain relief is possible on the moving end and/or the fixed end.

**Part No. structure**

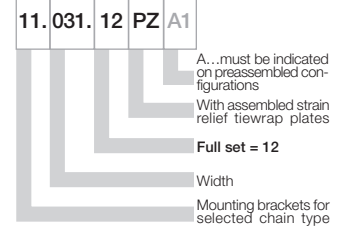

**Full set, for both ends:**

11.031.12.PZ +tiewrap plate

**Single-part order:**

11.031.1.PZ +tiewrap plate

Mounting bracket with bore

11.031.2.PZ +tiewrap plate

Mounting bracket with pin

For E-Chain®	Part No. full set with tiewrap plate	Part No. full set without tiewrap plate	Dim. A [mm]	Dim. B [mm]
11.031. ►	11.031.12.PZ	11.031.12.P	16	42

For the preassembled mode please add the index A1 ... A4 e.g. 11.031.12.PZ.A1

Phone +49- (0) 22 03-96 49-800  
Fax +49- (0) 22 03-96 49-222

