

Part No.		Bi [mm]	Ba [mm]	E4.32 [kg/m]	H4.32 [kg/m]	R4.32 [kg/m]
E4.32/H4.32/R4.32.05.	<input type="checkbox"/> .0*	50	73	1,567	1,425	2,450
E4.32/H4.32.06.	<input type="checkbox"/> .0	68	91	1,697	1,490	-
E4.32/H4.32/R4.32.07.	<input type="checkbox"/> .0	75	98	1,730	1,507	2,570
E4.32/H4.32/R4.32.087.	<input type="checkbox"/> .0 *R4.32.087 NEW	87	110	1,803	1,543	-
E4.32/H4.32/R4.32.10.	<input type="checkbox"/> .0	100	123	1,886	1,584	2,650
E4.32/H4.32/R4.32.11.	<input type="checkbox"/> .0	108	131	1,942	1,612	2,760
E4.32/H4.32.112.	<input type="checkbox"/> .0	112	136	1,956	1,619	-
E4.32/H4.32/R4.32.12.	<input type="checkbox"/> .0	125	148	2,069	1,676	2,850
E4.32/H4.32.137.	<input type="checkbox"/> .0	137	161	2,122	1,702	-
E4.32/H4.32/R4.32.15.	<input type="checkbox"/> .0	150	173	2,212	1,747	3,010
E4.32/H4.32.162.	<input type="checkbox"/> .0	162	186	2,240	1,762	-
E4.32/H4.32/R4.32.17.	<input type="checkbox"/> .0	168	191	2,323	1,803	3,210
E4.32/H4.32.18.	<input type="checkbox"/> .0	175	198	2,345	1,814	-
E4.32/H4.32.187.	<input type="checkbox"/> .0	187	211	2,392	1,837	-
E4.32/H4.32/R4.32.20.	<input type="checkbox"/> .0	200	223	2,518	1,900	3,410
E4.32/H4.32.212.	<input type="checkbox"/> .0	212	236	2,568	1,925	-
E4.32/H4.32.23.	<input type="checkbox"/> .0	225	248	2,669	1,976	-
E4.32/H4.32.237.	<input type="checkbox"/> .0	237	261	2,698	1,990	-
E4.32/H4.32/R4.32.25.	<input type="checkbox"/> .0	250	273	2,834	2,059	3,860
E4.32/H4.32.262.	<input type="checkbox"/> .0	262	286	2,917	2,100	-
E4.32/H4.32.28.	<input type="checkbox"/> .0	275	298	2,989	2,136	-
E4.32/H4.32.29.	<input type="checkbox"/> .0	287	311	3,023	2,153	-
E4.32/H4.32/R4.32.30.	<input type="checkbox"/> .0	300	323	3,151	2,217	4,250
E4.32/H4.32.312.	<input type="checkbox"/> .0	312	336	3,175	2,229	-
E4.32/H4.32.325.	<input type="checkbox"/> .0	325	348	3,277	2,280	-
E4.32/H4.32.337.	<input type="checkbox"/> .0	337	361	3,338	2,311	-
E4.32/H4.32.350.	<input type="checkbox"/> .0	350	373	3,565	2,424	-
E4.32/H4.32.362.	<input type="checkbox"/> .0	362	386	3,662	2,473	-
E4.32/H4.32.375.	<input type="checkbox"/> .0	375	398	3,735	2,509	-
E4.32/H4.32.387.	<input type="checkbox"/> .0	387	411	3,803	2,543	-
E4.32/H4.32.400.	<input type="checkbox"/> .0	400	423	3,868	2,575	-

*NEW in this catalog

*Removable lid only, no hinged option · **not available for R4.32

Available bending radii

R [mm] 063** 075** 100** 125 150 175 200 220 250 300

Supplement Part No. with required radius. Example: E4.32.30.300.0

0 = standard color, other colors ▶ page 5.65 · Pitch: 56 mm/link - Links/m = 18


TIP!
Hot Chips up to 850°C
E-Tubes that repel hot chips, up to 850°C
Some applications, depending on amount and size of the chips, left burn- and melt marks. That is no longer the case with the igus® "igumid HT" material.
Further information
www.igus.de/en/HT
phone +49-0 22 03-96 49-800

System E4.1
Inner height: 32 mm

Phone +49- (0) 22 03-96 49-800
Fax +49- (0) 22 03-96 49-222



Extender crossbar for large diameter hoses ▶ page 5.264

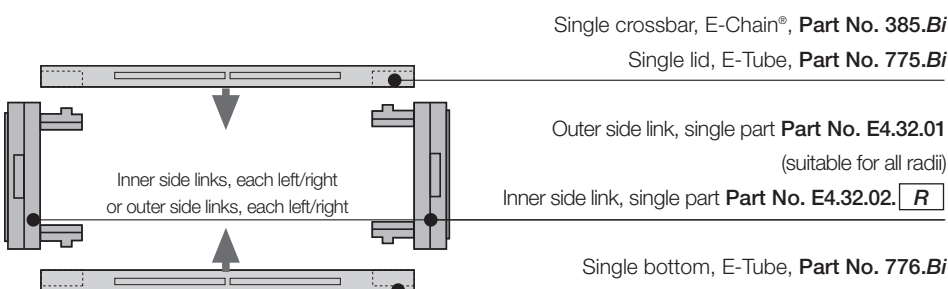

Part No. E-Chain® links, single parts

