

**Steel mounting brackets**


- One part for all chain widths
- Electrically conductive
- Universal use
- Material: Stainless steel: 1.4301



Part 1

Part 2

**Dimensions and order configurations**

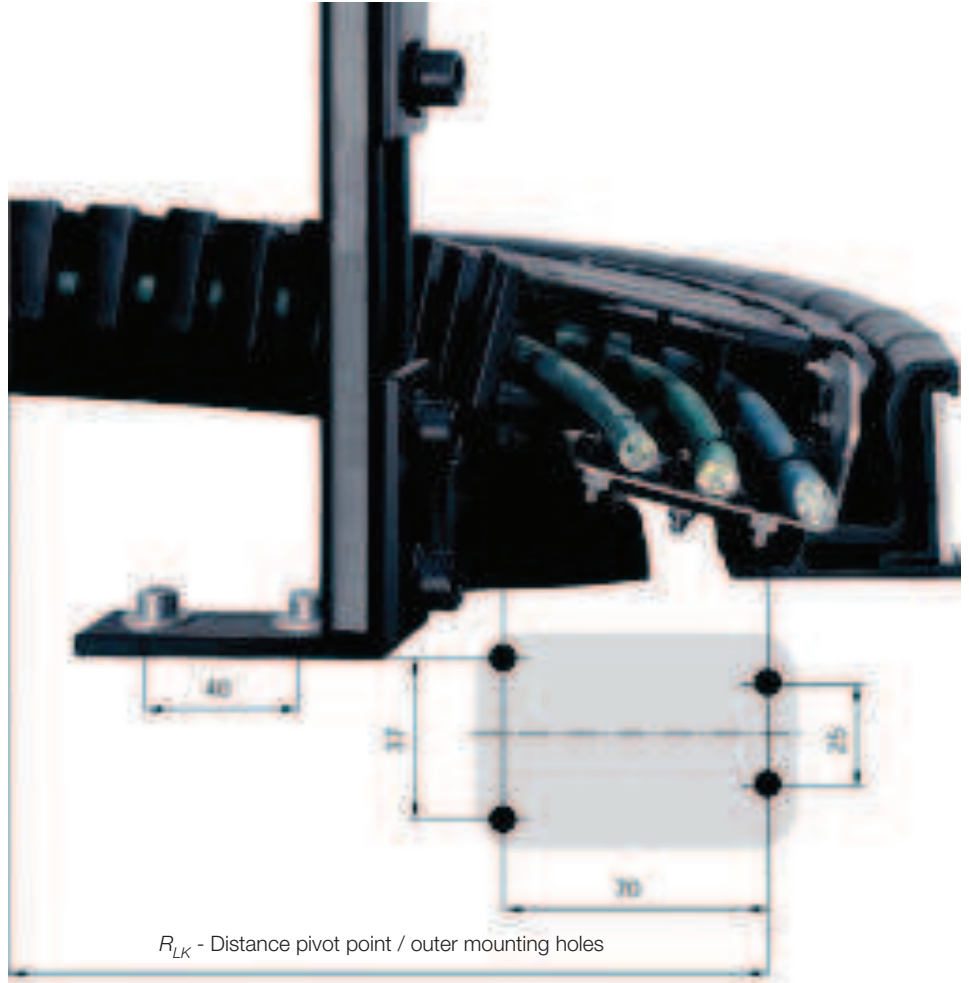


Phone +49- (0) 22 03-96 49-800  
Fax +49- (0) 22 03-96 49-222

igus® GmbH  
51147 Cologne

Internet: [www.igus.eu](http://www.igus.eu)  
E-mail: [info@igus.de](mailto:info@igus.de)

**Part No. structure**

 22080. 34. E



For E-Chain®	Part No. Full set	Part No. Part 1	Part No. Part 2
2208	22080. 34 .E	22080. 30 .E	22080. 40 .E
2808	28080. 34 .E	28080. 30 .E	28080. 40 .E
3808	38080. 34 .E	38080. 30 .E	38080. 40 .E
4008	40080. 34 .E	40080. 30 .E	40080. 40 .E

**Full set, for both ends**

22080. 34. E

**Single-part order - Part 1:**

22080. 30. E

**Single-part order - Part 2:**

22080. 40. E

The guide trough must be mounted at the fixed point of the TwisterChain®, as shown by the drilling template in the illustration. The following bolted connections are permitted:

- Bore Hole: 4 x Ø 6,6 - 7 mm
- Mounting only with bolts: 4 x bolts M6

Other connection dimensions for mounting the guide trough ► from page 2.71