



GERMK/GELMK

mm

igubal® Clevis Joints

Phone +49 - 22 03 - 96 49-145
Fax +49 - 22 03 - 96 49-334

igubal® GmbH
51147 Cologne

Internet www.igus.de
E-mail info@igus.de


52.6



Data in mm

Structure – part no.

G E ... M K-04

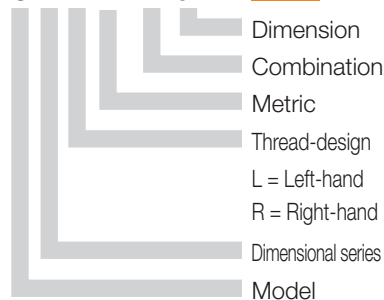

Special Properties

- Light weight
- Universal corrosion resistance
- High tensile strength
- Can be used in combination with series E rod ends



Material

igumid G

▶ Page 70.6

Load Data

igubal® – Clevis Joints with clevis pin and circlip

Part Number		Max. Static Axial Tensile Strength		Max. Radial Load	
Right-hand-thread	Left-hand-thread	Short Term	Long Term	Short Term	Long Term
		[N]	[N]	[N]	[N]
GERMK-04	GELMK-04	500	250	250	125
GERMK-04 M3.5	GELMK-04 M3.5	500	250	250	125
GERMK-05 DIN M4	GELMK-05 DIN M4	800	400	250	125
GERMK-05 DIN M5	GELMK-05 DIN M5	800	400	250	125
GERMK-05	GELMK-05	900	450	250	125
GERMK-05 DIN M5 LS	GELMK-05 DIN M5 LS	800	400	130	65
GERMK-06	GELMK-06	1300	650	300	150
GERMK-06 LS	GELMK-06 LS	1300	650	130	65
GERMK-08	GELMK-08	2100	1050	650	325
GERMK-10	GELMK-10	3000	1500	800	400
GERMK-10 F	GELMK-10 F	3000	1500	800	400
GERMK-12	GELMK-12	3500	1750	900	450
GERMK-12 F	GELMK-12 F	3500	1750	900	450
GERMK-14	GELMK-14	6100	3050	1000	500
GERMK-15	GELMK-15	2800	1400	1000	500
GERMK-16	GELMK-16	7000	3500	1200	600
GERMK-16 F	GELMK-16 F	7000	3500	1200	600
GERMK-17	GELMK-17	3600	1800	1200	600
GERMK-17 F	GELMK-17 F	3600	1800	1200	600
GERMK-20	GELMK-20	9000	4500	3000	1500
GERMK-20 M20	GELMK-20 M20	9000	4500	3000	1500



Single components:
clevis pin GBM and
circlip GSR

▶ Page 52.9

Lifetime calculation, CAD files and much more support ▶ www.igus.de/en/germ