

导向轴支座 块型侧开口标准型 / 上开口侧锁型



code
7天发货

选型指南

举例	型号		
标准	Code	D	H
	SHJF	20	30

Code	材质	表面处理	附件
SHJF	S45C	发黑	1个内六角螺栓
SHJFN		镀镍	
SHJFS	SUS304	-	1个内六角螺栓 (SUS)
SHJFA	A6063	本色阳极	

侧开口标准型

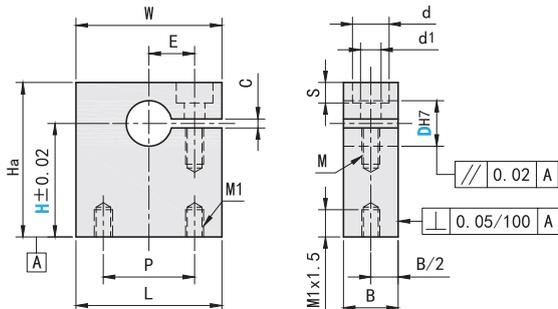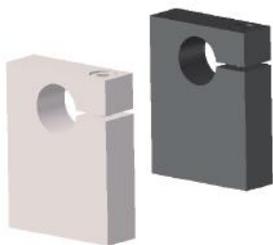


注: () 内的尺寸为铝合金型的尺寸

型号		H 选择		L	B	Ha	P	E	M	d1	d	S	C	M1
Code	D													
SHJF SHJFN SHJFS SHJFA	8	25	30	26	12	H+7	16	8	M4深8	4.5	8	4.6	2	4
	10	25	30	32		H+9	20	10						
	12	25	30			H+11	21	10.5						
	13	25	30	H+12		23	11.5							
	15	25	30	40	16	H+15	28	14	M6深12	6.6	11	6.7	6	
	16	25	30	40		34	17							
	18	30	40	50	50	H+18	36	18	M8深16	9	14	9.1	3	8
	20	30	40	50		H+21	48	24						
	25	30	40	50	70	H+24	56	28	M8深16	9	14	9.1	3	8
	30	40	50	60		H+27	56	28						
35	40	50	60	76	H+27	56	28	M8深16	9	14	9.1	3	8	
40	40	50	60		H+27	56	28							

上开口侧锁型



Code	材质	表面处理	附件
SHJG	S45C	发黑	1个内六角螺栓
SHJGN		镀镍	
SHJGS	SUS304	-	1个内六角螺栓 (SUS)
SHJGA	A6063	本色阳极	

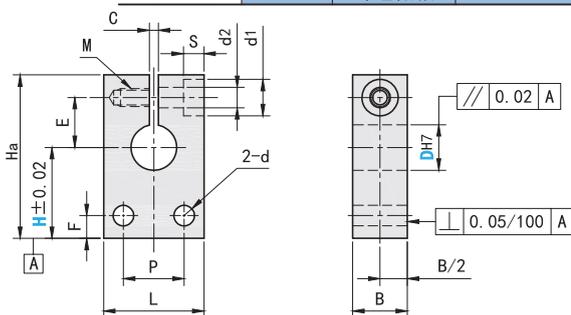

注: () 内的尺寸为铝合金型的尺寸

型号		H 选择		L	B	Ha	F	P	E	d	M	d2	d1	S	C	
Code	D															
SHJG SHJGN SHJGS SHJGA	8	20	25	30	12	H+16	5	10	11	4.5	M4深8	4.5	8	4.6	2	
	10	20	25	30		H+18		14	13							
	12	20	25	30		H+20		16	15							
	13	20	25	30		H+26		18	18							
	15	25	30	40	16	H+26	7	18	18	6.6	M6深12	6.6	11	6.7		
	16	25	30	40		H+28		24	21							
	18	25	30	40	50	32	H+33	10	24	24	9	M8深16	9	14	9.1	3
	20	25	30	40	50		H+36		32	27						
	25	30	40	50	38	H+38	20	24	24	9	M8深16	9	14	9.1	3	
	30	30	40	50		60		H+38	32							29
35	40	50	60	50	H+38	20	24	24	9	M8深16	9	14	9.1	3		
40	40	50	60		H+38		32	29								

单轴机械手

直线模组

单轴组件

手动组件

防尘罩

导向轴

导向轴支座

固定环

直线轴承

直线轴承组件

微型滚珠衬套

无油衬套及组件

直线导轨

导轨配件

滚珠丝杠

丝杠支座

梯形丝杠及支座

位置显示器

抽屉导轨

线性滑轨

花键