



滚珠轴承组件 轴台型 · 菱形法兰型

code  
5天发货

选型指南

举例	型号
Code	D
标准	PBCT 15
	PBCH 15

■轴台型

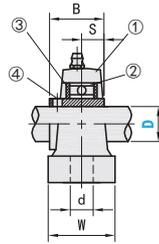
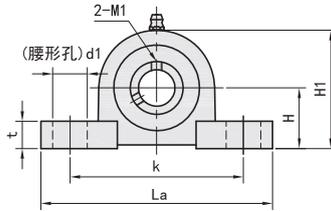


- ◆精度: JIS B 1558  
JIS B 1514  
JIS B 1559
- ◆轴承箱轴承座直径的精度: H7 (间隙配合)
- ◆使用温度: -15~+100°C

型号		零件	材质
国产	进口		
C-PBCT	PBCT	①固定座	FC200
		②轴承	SUJ2
		③橡胶密封圈	丁腈橡胶 (NBR)
		④止动螺丝	SCM435

型号		H	H1	La	k	t	W	d1	d	M1	B	S	基本额定负载	
Code	D												Cr(动)KN	Cr(静)KN
PBCT C-PBCT	12	30.2	62	127	95	15	38	19	13	M6×0.75	31	12.7	12.8	6.6
	15	30.2	62	127	95	15	38	19	13		31	12.7	12.8	6.6
	17	30.2	62	127	95	15	38	19	13		31	12.7	12.8	6.6
	20	33.3	65	127	95	15	38	19	13		31	12.7	12.8	6.6
	25	36.5	70	140	105	16	38	16	13		34.1	14.3	14	7.9
	30	42.9	83	165	121	18	48	21	17		38.1	15.9	19.6	11.3
	35	47.6	94	167	127	19	48	21	17	M8×1.0	42.9	17.5	25.9	15.4
	40	49.2	100	184	137	19	54	25	17		49.2	19	29.3	17.9
	45	54	108	190	146	20	54	22	17		49.2	19	33	20.5
	50	57.2	114	206	159	22	60	25	20		M10×1.25	51.6	19	35.5

■菱形法兰型

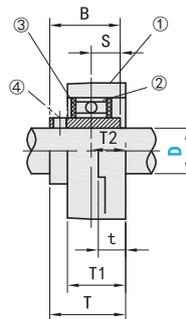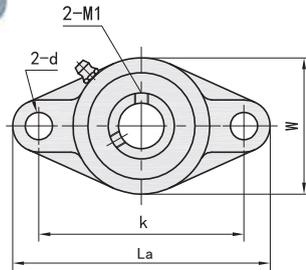

- ◆精度: JIS B 1558  
JIS B 1514  
JIS B 1559
- ◆轴承箱轴承座直径的精度: H7 (间隙配合)
- ◆使用温度: -15~+100°C

型号		零件	材质
国产	进口		
C-PBCH	PBCH	①固定座	FC200
		②轴承	SUJ2
		③橡胶密封圈	丁腈橡胶 (NBR)
		④止动螺丝	SCM435

型号		La	k	W	t	T	T1	T2	d	M1	B	S	基本额定负载	
Code	D												Cr(动)KN	Cr(静)KN
PBCH C-PBCH	12	113	90	60	12	33.3	25.5	15	12	M6×0.75	31	12.7	12.8	6.6
	15	113	90	60	12	33.3	25.5	15	12		31	12.7	12.8	6.6
	17	113	90	60	12	33.3	25.5	15	12		31	12.7	12.8	6.6
	20	113	90	60	12	33.3	25.5	15	12		31	12.7	12.8	6.6
	25	130	99	68	14	35.8	27	16	16		34.1	14.3	14	7.9
	30	148	117	80	14	40.2	31	18	16		38.1	15.9	19.6	11.3
	35	161	130	90	16	44.4	34	19	16	M8×1.0	42.9	17.5	25.9	15.4
	40	175	144	100	16	51.2	36	21	16		49.2	19	29.3	17.9
	45	188	148	108	18	52.2	38	22	19		49.2	19	33	20.5
	50	197	157	115	18	54.6	40	22	19		M10×1.25	51.6	19	35.5