


小径滚珠轴承 双盖式

5天发货

选型指南

举例	型号
标准	BB608ZZ

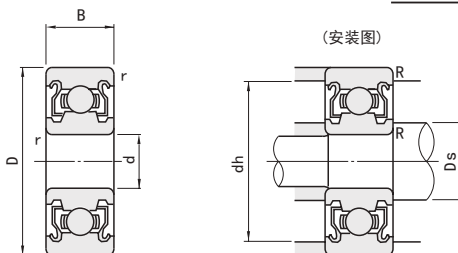

◆轴承精度: GB 307 P0
JIS B 1514 0级

Code	产地	材质
BB6□□ZZ	进口	SUJ2
BB6□□AZZ		
C-BB6□□ZZ	国产	
C-BB6□□AZZ		

分度盘

行星
减速机

联轴器·
万向节

免键衬套

轴承

凸轮·
滚子轴承

轴承座
组件

齿轮齿条·
磁力轮

转轴

悬臂销

铰链销

支点用
台阶螺丝

型号		d	D	B	r (min)	基本额定负载		容许转速 rpm (参考)	安装尺寸			重量 (g) (参考)
国产	进口					Cr (动) N	Cor (静) N		Ds (min)	dh (max)	R (max)	
C-BB682ZZ	BB682ZZ	2	5	2.3	0.08	169	50	85000	2.7	3.9	0.08	0.17
C-BB692ZZ	BB692ZZ		6	3	0.15	330	98	75000	3	4.8	0.15	0.38
C-BB602ZZ	BB602ZZ		7	3.5		385	127	60000	3.2	5.8	0.15	0.58
C-BB682AZZ	BB682AZZ	2.5	6	2.6	0.08	208	74	71000	3.7	4.9	0.08	0.29
C-BB692AZZ	BB692AZZ		7	3.5	0.15	385	127	63000	3.85	5.65	0.15	0.55
C-BB673ZZ	BB673ZZ	3	6	2.5	0.1	208	74	71000	3.6	5.4	0.08	0.2
C-BB683ZZ	BB683ZZ		7	3	0.1	390	130	63000	3.9	5.8	0.1	0.45
C-BB693ZZ	BB693ZZ		8	4	0.15	560	179	60000	4.2	6.8	0.15	0.83
C-BB603ZZ	BB603ZZ		9	5	0.15	570	187	56000		7.8	0.15	1.45
C-BB623ZZ	BB623ZZ	10	4	630		218	50000	8.8	0.15	1.66		
C-BB633ZZ	BB633ZZ	13	5	0.2		1300	485	40000	11.4	0.2	3.33	
C-BB674ZZ	BB674ZZ	4	7	2.5	0.1	222	88	60000	4.6	6.4	0.08	0.29
C-BB684ZZ	BB684ZZ		9	4	0.1	640	224	53000	5	7.8	0.1	1.01
C-BB694ZZ	BB694ZZ		11		0.15	715	276	48000	5.2	9.8	0.15	1.75
C-BB604ZZ	BB604ZZ		12	5	0.2	957	350	48000	5.6	10.4	0.2	2.29
C-BB624ZZ	BB624ZZ		13			1300	485	40000	5.6	11.4	0.2	3.04
C-BB634ZZ	BB634ZZ		16			1340	523	36000	6	14	0.3	5.21
C-BB675ZZ	BB675ZZ	8	2.5	0.1	218	131	53000	5.8	7.4	0.1	0.34	
C-BB685ZZ	BB685ZZ	5	11	5	0.15	715	281	45000	6.2	9.8	0.2	1.96
C-BB695ZZ	BB695ZZ		13	4	0.2	1080	430	43000	6.6	11.4		2.5
C-BB605ZZ	BB605ZZ		14	5	0.3	1330	505	40000		12.4	0.3	3.48
C-BB625ZZ	BB625ZZ		16			1730	670	36000	7	14		4.86
C-BB635ZZ	BB635ZZ	19	6	2336	835	32000	7	17	8.34			
C-BB676ZZ	BB676ZZ	6	10	3	0.1	495	218	45000	7.04	9.3	0.1	0.68
C-BB686ZZ	BB686ZZ		13	5	0.15	1080	440	40000	7	11.8	0.2	2.69
C-BB696ZZ	BB696ZZ		15		0.2	1350	530	40000	7.6	13.4		3.72
C-BB606ZZ	BB606ZZ		17	6	0.3	2190	835	38000	8	15	0.3	6.08
C-BB626ZZ	BB626ZZ		19			2340	885	32000		17		7.94
C-BB636ZZ	BB636ZZ		22			7	3333	1423	30000	8		20
C-BB678ZZ	BB678ZZ	12	3.5	0.1	543	274	40000	9.05	11.33	0.1	0.97	
C-BB688ZZ	BB688ZZ	8	16	5	0.2	1610	710	36000	9.6	14.4	0.2	4.02
C-BB698ZZ	BB698ZZ		19	6	0.3	1990	865	36000		17		7.18
C-BB608ZZ	BB608ZZ		22	7		3350	1400	34000	10	20	12	
C-BB628ZZ	BB628ZZ		24	8		4000	1590	28000	10	22	17	
C-BB638ZZ	BB638ZZ		28	9		4563	1983	28000		26	30.3	