

带止推滚珠滚针轴承 · 带止推滚针滚针轴承 标准型



code
5天发货

旋转运动部品

选型指南

举例
标准
型号
NKX10Z
NKXR15Z



■带止推滚珠滚针轴承

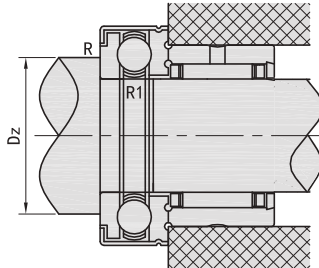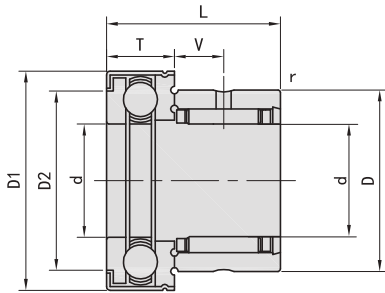

- ◆产地: 进口\国产
- ◆特点: 同时承受轴向和径向负载
- ◆材质: SUJ2 精度等级: 0级

型号		d	D	L	T	r (min.)	D1	V	D2	径向载荷		轴向载荷		极限转速 (rpm)	重量 (g)	安装尺寸		
国产	进口									Cr动 (KN)	Cor静 (KN)	Cr动 (KN)	Cor静 (KN)			Dz (min.)	R (max.)	R1 (max.)
C-NKX10Z	NKX10Z	10	19	23	9	0.3	25.2	6.5	19.7	6.2	7.8	10	14	7200	40.9	18	0.3	0.3
C-NKX12Z	NKX12Z	12	21	23	9	0.3	27.2	6.5	21.7	9	11	10.3	15.4	6600	46	20	0.3	0.3
C-NKX15Z	NKX15Z	15	24	23	9	0.3	29.2	6.5	23.7	10.7	12.7	10.5	16.8	5700	54.6	23	0.3	0.3
C-NKX17Z	NKX17Z	17	26	25	9	0.3	31.2	8	25.7	11.9	15	10.8	18.2	5100	64.5	25	0.3	0.3
C-NKX20Z	NKX20Z	20	30	30	10	0.3	36.2	10.5	30.7	16.4	23.8	14.3	24.7	4500	103.5	29	0.3	0.3
C-NKX25Z	NKX25Z	25	37	30	11	0.6	43.2	9.5	37.7	18.8	30.5	19.6	37.5	3600	159.5	35	0.6	0.3
C-NKX30Z	NKX30Z	30	42	30	11	0.6	48.2	9.5	42.7	22.6	36	20.4	42	3000	180.8	40	0.6	0.3
C-NKX35Z	NKX35Z	35	47	30	12	0.6	53.2	9	47.7	24.3	41.5	21.2	47	2700	207	45	0.6	0.3
C-NKX40Z	NKX40Z	40	52	32	13	0.6	61.2	10	55.7	26	47	27	63	2400	252.2	52	0.6	0.3
C-NKX45Z	NKX45Z	45	58	32	14	0.6	66.5	9	60.5	27.5	53	28	69	2100	315.8	57	0.6	0.3
C-NKX50Z	NKX50Z	50	62	35	14	0.6	71.5	10	65.5	38	74	29	75	1900	370.8	62	0.6	0.6
C-NKX60Z	NKX60Z	60	72	40	17	1	86.5	12	80.5	42	90	41.5	113	1600	542	75	1	1

■带止推滚针滚针轴承

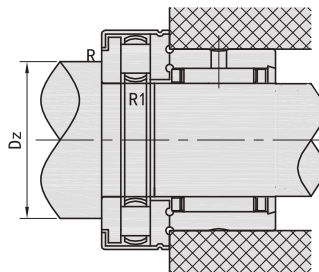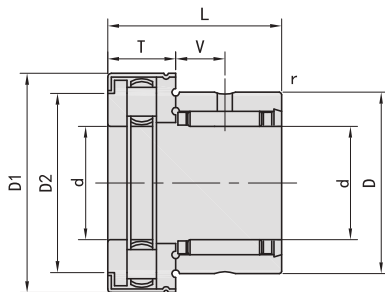

- ◆产地: 进口\国产
- ◆特点: 同时承受轴向和径向负载
- ◆材质: SUJ2 精度等级: 0级

型号		d	D	L	T	r (min.)	D1	V	D2	径向载荷		轴向载荷		极限转速 (rpm)	重量 (g)	安装尺寸		
国产	进口									Cr动 (KN)	Cor静 (KN)	Cr动 (KN)	Cor静 (KN)			Dz (min.)	R (max.)	R1 (max.)
C-NKXR15Z	NKXR15Z	15	24	23	9	0.3	29	6.5	23.7	9	9.9	10.9	24.5	7800	45	25	0.3	0.3
C-NKXR17Z	NKXR17Z	17	26	25	9	0.3	31	8	25.7	9.9	13.8	12.8	32.8	7200	53	27	0.3	0.3
C-NKXR20Z	NKXR20Z	20	30	30	10	0.3	36	10.5	30.7	12	20.5	20.9	50.6	6000	84	32	0.3	0.3
C-NKXR25Z	NKXR25Z	25	37	30	11	0.6	43	9.5	37.7	14.5	29.5	31.5	73.5	5100	125	39	0.6	0.3
C-NKXR30Z	NKXR30Z	30	42	30	11	0.6	48	9.5	42.7	19.6	32.5	32.8	82.5	4500	141	44	0.6	0.3
C-NKXR35Z	NKXR35Z	35	47	30	12	0.6	53	9	47.7	20.5	39.6	36.8	96	3900	165	49	0.6	0.3
C-NKXR40Z	NKXR40Z	40	52	32	13	0.6	61	10	55.7	22.3	44.5	54	139	3600	214	56	0.6	0.3
C-NKXR45Z	NKXR45Z	45	58	32	14	0.6	66.5	9	60.5	24.5	51	57.5	148	3000	260	61	0.6	0.3
C-NKXR50Z	NKXR50Z	50	62	35	14	0.6	71.5	10	65.5	34.8	70.8	60.5	169	2800	288	66	0.6	0.6

分度盘

行星减速机

联轴器·万向节

免键衬套

轴承

凸轮·滚子轴承

轴承座组件

齿轮齿条·磁力轮

转轴

悬臂销

铰链销

支点用台阶螺丝