

同步带 MXL · XL型 经济型

code
5天发货


选型指南

标准	Code	型号	皮带编号	公称宽度
举例	C-TBG	236MXL	037	

种类	齿距	2P	Lr	h	Ha	Rr	Ra
MXL	2.03	40°	1.14	0.51	1.14	0.13	0.13
XL	5.08	50°	2.57	1.27	2.30	0.38	0.38



C-TBG (氯丁橡胶)

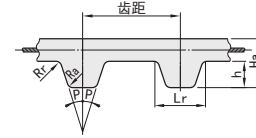

■ 种类 MXL (齿距: 2.032mm)

MXL (齿距: 2.032mm)					XL (齿距: 5.08mm)				
Code	皮带编号	皮带公称宽度	齿数	皮带周长 (mm)	Code	皮带编号	皮带公称宽度	齿数	皮带周长 (mm)
C-TBG	50MXL		50	101.60	C-TBG	180MXL		180	365.76
	51MXL		51	103.63		184MXL		184	373.89
	52MXL		52	105.66		189MXL		189	384.05
	53MXL		53	107.70		190MXL		190	386.08
	54MXL		54	109.73		192MXL		192	390.14
	55MXL		55	111.76		194MXL		194	394.21
	56MXL		56	113.79		195MXL		195	396.24
	57MXL		57	115.82		197MXL		197	400.30
	58MXL		58	117.86		200MXL		200	406.40
	59MXL		59	119.89		205MXL		205	416.56
	60MXL		60	121.92		210MXL		210	426.72
	61MXL		61	123.95		212MXL		212	430.78
	62MXL		62	125.98		216MXL		216	438.91
	63MXL		63	128.02		218MXL		218	442.98
	64MXL		64	130.05		219MXL		219	445.01
	65MXL		65	132.08		221MXL		221	449.07
	66MXL		66	134.11		224MXL		224	455.17
	67MXL		67	136.14		225MXL		225	457.20
	68MXL		68	138.18		229MXL		229	465.33
	69MXL		69	140.21		232MXL		232	471.42
	70MXL	019 (4.8mm)	70	142.24		235MXL	019 (4.8mm)	235	477.52
	71MXL		71	144.27		236MXL		236	479.55
	72MXL		72	146.30		239MXL		239	485.65
	73MXL	025 (6.4mm)	73	148.34		240MXL	025 (6.4mm)	240	487.68
	75MXL		75	152.40		245MXL		245	497.84
	76MXL		76	154.43		250MXL		250	508.00
	77MXL		77	156.46		256MXL		256	520.19
	78MXL	037 (9.5mm)	78	158.50		260MXL	037 (9.5mm)	260	528.32
	79MXL		79	160.53		265MXL		265	538.48
	80MXL		80	162.56		275MXL		275	558.80
	81MXL		81	164.59		280MXL		280	568.96
	82MXL	050 (12.7mm)	82	166.62		285MXL	050 (12.7mm)	285	579.12
	83MXL		83	168.66		290MXL		290	589.28
	84MXL		84	170.69		292MXL		292	593.34
	85MXL		85	172.72		300MXL		300	609.60
	86MXL		86	174.75		310MXL		310	629.92
	87MXL		87	176.78		312MXL		312	633.98
	88MXL		88	178.82		318MXL		318	646.18
	89MXL		89	180.85		322MXL		322	654.30
	90MXL		90	182.88		328MXL		328	666.50
	91MXL		91	184.91		332MXL		332	674.62
	92MXL		92	186.94		347MXL		347	705.10
	93MXL		93	188.98		350MXL		350	711.20
	94MXL		94	191.01		358MXL		358	727.46
	95MXL		95	193.04		378MXL		378	768.10
	96MXL		96	195.07		380MXL		380	772.16
	97MXL		97	197.10		400MXL		400	812.80
	98MXL		98	199.14		453MXL		453	920.50
	99MXL		99	201.17		500MXL		500	1016.00
	100MXL		100	203.20		522MXL		522	1060.70
	101MXL		101	205.23		1012MXL		1012	2056.38
	102MXL		102	207.26		1137MXL		1137	2310.38
	103MXL		103	209.30		1463MXL		1463	2972.82

同步带 MXL · XL型 经济型

code
5天发货

■ 种类 XL (齿距: 5.08mm)

MXL (齿距: 2.032mm)					XL (齿距: 5.08mm)				
Code	皮带编号	皮带公称宽度	齿数	皮带周长 (mm)	Code	皮带编号	皮带公称宽度	齿数	皮带周长 (mm)
	54XL		27	137.16		176XL		88	447.04
	56XL		28	142.24		178XL		89	452.12
	58XL		29	147.32		180XL		90	457.20
	60XL		30	152.40		182XL		91	462.28
	62XL		31	157.48		184XL		92	467.36
	64XL		32	162.56		186XL		93	472.44
	66XL		33	167.64		188XL		94	477.52
	68XL		34	172.72		190XL		95	482.60
	70XL		35	177.80		192XL		96	487.68
	72XL		36	182.88		194XL		97	492.76
	74XL		37	187.96		196XL		98	497.84
	76XL		38	193.04		198XL		99	502.92
	78XL		39	198.12		200XL		100	508.00
	80XL		40	203.20		202XL		101	513.08
	82XL		41	208.28		204XL		102	518.16
	84XL		42	213.36		206XL		103	523.24
	86XL		43	218.44		208XL		104	528.32
	88XL		44	223.52		210XL		105	533.40
	90XL		45	228.60		212XL		106	538.48
	92XL		46	233.68		214XL		107	543.56
	94XL		47	238.76		216XL		108	548.64
	96XL		48	243.84		218XL		109	553.72
	98XL		49	248.92		220XL		110	558.80
	100XL		50	254.00		222XL	025 (6.4mm)	111	563.88
	102XL	025 (6.4mm)	51	259.08		224XL		112	568.96
	104XL		52	264.16		226XL		113	574.04
	106XL		53	269.24		228XL		114	579.12
	108XL	031 (7.9mm)	54	274.32		230XL	031 (7.9mm)	115	584.20
	110XL		55	279.40		234XL		117	594.36
	112XL		56	284.48		236XL		118	599.44
	114XL	037 (9.5mm)	57	289.56		240XL	037 (9.5mm)	120	609.60
	116XL		58	294.64		244XL		122	619.76
	118XL		59	299.72		248XL		124	629.92
	120XL		60	304.80		250XL		125	635.00
	122XL		61	309.88		252XL		126	640.08
	124XL	050 (12.7mm)	62	314.96		254XL	050 (12.7mm)	127	645.16
	126XL		63	320.04		256XL		128	650.24
	128XL		64	325.12		258XL		129	655.32
	130XL		65	330.20		260XL		130	660.40
	132XL		66	335.28		264XL		132	670.56
	134XL		67	340.36		266XL		133	675.64
	136XL		68	345.44		268XL		134	680.72
	138XL		69	350.52		270XL		135	685.80
	140XL		70	355.60		272XL		136	690.88
	142XL		71	360.68		274XL		137	695.96
	144XL		72	365.76		276XL		138	701.04
	146XL		73	370.84		278XL		139	706.12
	148XL		74	375.92		280XL		140	711.20
	150XL		75	381.00		282XL		141	716.28
	152XL		76	386.08		286XL		143	726.44
	154XL		77	391.16		290XL		145	736.60
	156XL		78	396.24		296XL		148	751.84
	158XL		79	401.32		300XL		150	762.00
	160XL		80	406.40		302XL		151	767.08
	162XL		81	411.48		304XL		152	772.16
	164XL		82	416.56		306XL		153	777.24
	166XL		83	421.64		310XL		155	787.40
	168XL		84	426.72		312XL		156	792.48
	170XL		85	431.80		314XL		157	797.56
	172XL		86	436.88		316XL		158	802.64
	174XL		87	441.96					

传送部品

传送部品

- 输送机
- 同步带轮
- 免键同步带轮
- 同步惰轮
- 同步带
- 链轮链条
- 滚轮
- 传送类零件
- 平皮带
- 平皮带滑轮
- 圆皮带
- 圆皮带滑轮

- 输送机
- 同步带轮
- 免键同步带轮
- 同步惰轮
- 同步带
- 链轮链条
- 滚轮
- 传送类零件
- 平皮带
- 平皮带滑轮
- 圆皮带
- 圆皮带滑轮