

同步带 S5M · S8M · S14M型

code 5天发货


选型指南

举例	型号	公称宽度
Code	皮带编号	
标准	TBG 625 S5M	250
	TBG 480 S8M	250



Code	材质	
TBG	背面橡胶	氯丁橡胶
	齿橡胶	
	芯线	玻璃纤维线S·Z形捻交互连续
	底布	尼龙织布

TBG (橡胶)

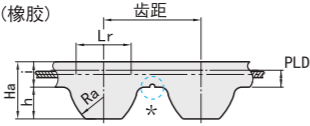

◆使用温度:
◆橡胶: -30~90°C 聚氨酯: 0~80°C
注: TBG的齿根不带槽口
注: 皮带周长为芯线长度。

种类	齿距	Ra	Lr	Ha	h	i	PLD	单位重量 g/m(宽度: 10mm)
S5M	5	3.25	3.25	3.41	1.91	1.5	0.48	34
S8M	8	5.2	5.2	5.3	3.05	2.25	0.686	52
S14M	14	9.1	9.1	10.2	5.3	4.9	1.397	100

■ 种类 S5M (齿距: 5mm)

Code	型号		齿数	皮带周长 (mm)
	皮带编号	皮带公称宽度		
TBG (橡胶)	225 S5M	100 (10mm)	45	225
	230 S5M		46	230
	255 S5M		51	255
	260 S5M		52	260
	295 S5M		59	295
	300 S5M		60	300
	305 S5M		61	305
	320 S5M		64	320
	325 S5M		65	325
	340 S5M		68	340
	350 S5M		70	350
	360 S5M		72	360
	370 S5M		74	370
	375 S5M		75	375
	380 S5M		76	380
	390 S5M		78	390
	400 S5M		80	400
	415 S5M		83	415
	425 S5M		85	425
	440 S5M		88	440
450 S5M	90	450		
475 S5M	95	475		
490 S5M	98	490		
500 S5M	100	500		
520 S5M	104	520		
525 S5M	105	525		
530 S5M	106	530		
545 S5M	109	545		
550 S5M	110	550		
560 S5M	112	560		
575 S5M	115	575		
590 S5M	118	590		
595 S5M	119	595		
600 S5M	120	600		
625 S5M	125	625		
640 S5M	128	640		
650 S5M	130	650		
670 S5M	134	670		
675 S5M	135	675		
690 S5M	138	690		
695 S5M	139	695		
700 S5M	140	700		
720 S5M	144	720		
725 S5M	145	725		
730 S5M	146	730		
750 S5M	150	750		

■ 种类 S5M (齿距: 5mm)

Code	型号		齿数	皮带周长 (mm)
	皮带编号	皮带公称宽度		
TBG (橡胶)	765 S5M	100 (10mm)	153	765
	780 S5M		156	780
	800 S5M		160	800
	810 S5M		162	810
	830 S5M		166	830
	845 S5M		169	845
	850 S5M		170	850
	870 S5M		174	870
	890 S5M		178	890
	900 S5M		180	900
	930 S5M		186	930
	950 S5M		190	950
	975 S5M		195	975
	1000 S5M		200	1000
	1025 S5M		205	1025
	1050 S5M		210	1050
	1055 S5M		211	1055
	1090 S5M		218	1090
	1100 S5M		220	1100
	1105 S5M		221	1105
1115 S5M	223	1115		
1120 S5M	224	1120		
1125 S5M	225	1125		
1135 S5M	227	1135		
1145 S5M	229	1145		
1160 S5M	232	1160		
1165 S5M	233	1165		
1195 S5M	239	1195		
1250 S5M	250	1250		
1270 S5M	254	1270		
1295 S5M	259	1295		
1350 S5M	270	1350		
1420 S5M	284	1420		
1475 S5M	295	1475		
1500 S5M	300	1500		
1505 S5M	301	1505		
1530 S5M	306	1530		
1595 S5M	319	1595		
1605 S5M	321	1605		
1680 S5M	336	1680		
1715 S5M	343	1715		
1800 S5M	360	1800		
2000 S5M	400	2000		
2145 S5M	429	2145		
2255 S5M	451	2255		
2480 S5M	496	2480		

同步带 S5M · S8M · S14M型

code 5天发货

■ 种类 S8M (齿距: 8mm)

Code	型号		齿数	皮带周长 (mm)
	皮带编号	皮带公称宽度		
TBG (橡胶)	480 S8M	150 (15mm)	60	480
	520 S8M		65	520
	584 S8M		73	584
	600 S8M		75	600
	632 S8M		79	632
	656 S8M		82	656
	712 S8M		89	712
	720 S8M		90	720
	760 S8M		95	760
	800 S8M		100	800
	824 S8M		103	824
	848 S8M		106	848
	880 S8M		110	880
	896 S8M		112	896
	920 S8M		115	920
	944 S8M		118	944
	960 S8M		120	960
	976 S8M		122	976
	1000 S8M		125	1000
	1056 S8M		132	1056
1080 S8M	135	1080		
1120 S8M	140	1120		
1136 S8M	142	1136		
1200 S8M	150	1200		
1280 S8M	160	1280		
1304 S8M	163	1304		
1360 S8M	170	1360		
1400 S8M	175	1400		
1440 S8M	180	1440		
1480 S8M	185	1480		
1520 S8M	190	1520		
1600 S8M	200	1600		
1680 S8M	210	1680		
1776 S8M	222	1776		
1800 S8M	225	1800		
1912 S8M	239	1912		
2000 S8M	250	2000		
2304 S8M	288	2304		
2400 S8M	300	2400		
2496 S8M	312	2496		
2600 S8M	325	2600		
2800 S8M	350	2800		
3200 S8M	400	3200		
3680 S8M	460	3680		

■ 种类 S14M (齿距: 14mm)

Code	型号		齿数	皮带周长 (mm)
	皮带编号	皮带公称宽度		
TBG (橡胶)	1008 S14M	400 (40mm)	72	1008
	1120 S14M		80	1120
	1190 S14M		85	1190
	1246 S14M		89	1246
	1400 S14M		100	1400
	1540 S14M		110	1540
	1610 S14M		115	1610
	1652 S14M		118	1652
	1778 S14M		127	1778
	1806 S14M		129	1806
	1890 S14M		135	1890
	2002 S14M		143	2002
	2100 S14M		150	2100
	2240 S14M		160	2240
	2310 S14M		165	2310
	2380 S14M		170	2380
	2450 S14M		175	2450
	2506 S14M		179	2506
	2590 S14M		185	2590
	2660 S14M		190	2660
2800 S14M	200	2800		
3150 S14M	225	3150		
3500 S14M	250	3500		
3556 S14M	254	3556		
3850 S14M	275	3850		
4004 S14M	286	4004		
4508 S14M	322	4508		
5012 S14M	358	5012		