


气动接头 快速接头



选型指南

标准	举例	型号		-	k	型号		-	k
		Code	No.			Code	No.		
		CTS	4	-	M5	CTSM	4	-	M5

快速接头

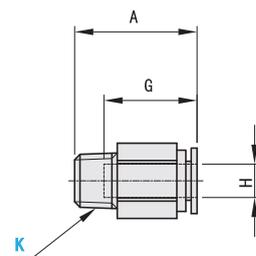

Code	材质	表面处理
CTS	PBT	-
CTSM	黄铜	镀镍

型号		K	配管直径 H	螺纹尺寸 K	A	G
Code	No.					
CTS	4	M5	4	M5×0.8	20.1	14.9
	4	01		R1/8	21.3	
	4	02		R1/4	21	
	6	M5	6	M5×0.8	22.2	17
	6	01		R1/8	22.6	
	6	02		R1/4	24.6	
	6	03		R3/8	23.6	
	8	01	8	R1/8	27.9	18.1
	8	02		R1/4	26.6	
	8	03		R3/8	24	
	10	01	10	R1/8	30.3	20.2
	10	02		R1/4	30	
	10	03		R3/8	29.5	
	12	02	12	R1/4	35.9	23.3
	12	03		R3/8	31.9	
12	04	R1/2		33.9		

型号		K	配管直径 H	螺纹尺寸 K	A	G
Code	No.					
迷你型 CTSM	4	M5	4	M5×0.8	20.1	14.9
	4	01		R1/8	21.3	
	6	M5	6	M5×0.8	22.2	17
	6	01		R1/8	22.6	

气动部品 · 液压配件

真空发生器

真空吸盘

气动接头

气动配件

压头

浮动接头

连接类零件

电磁阀

手动阀

空气调理

气缸

流体控制阀

压力桶

点胶机