

### Mounting plates

#### Screw-fastened, small

**Material:**

- Sheet steel

**Surface finish:**

- Zinc-plated


**Supply includes:**

- Assembly screws

Packs of	Model No.
4 pc(s).	4532.000

**Technical details:**

Available on the Internet

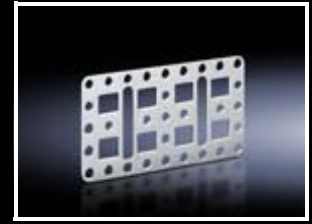

### Mounting plate TS

#### with integral top-hat rail

For direct snap-mounting of components such as speed control, enclosure internal thermostat and hygostat.

**Material:**

- Sheet steel

**Surface finish:**

- Zinc-plated

**Supply includes:**

- Mounting plate (mounting accessories included)

Packs of	Model No.
1 pc(s).	7526.964



### Mounting bracket

May be screw-fastened onto all enclosures and mounting parts with system punchings on a 25 mm pitch pattern.

**Material:**

- Sheet steel

**Surface finish:**

- Zinc-plated

**Supply includes:**

- Assembly screws

Packs of	Model No.
4 pc(s).	4597.000



**Accessories:**

- Screws, see page 625
- Cable tie for fast assembly 2597.000, see page 667

**Technical details:**

Available on the Internet



### Mounting bracket

#### for interior installation

For installing punched sections with mounting flanges and support strips in:

- Comfort Panel horizontal/vertical from 74 mm installation depth

or for installing in:

- Optipanel from an installation depth of 100 mm

**Material:**

- Sheet steel

**Surface finish:**

- Zinc-plated

**Supply includes:**

- Assembly parts

Packs of	Model No.
4 pc(s).	6205.100

**Technical details:**

Available on the Internet



		Comfort Panel	Page
		Front panel width 482.6 mm (19")	
Punched sections with mounting flanges	Horizontal	8612.150	606
	Vertical		
Support strips	Horizontal	4695.000	609
	Vertical		