


# Cable management

## 482.6 mm (19") cable management

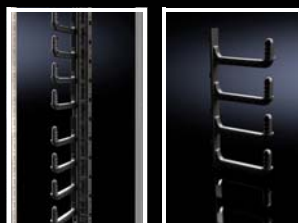

### Cable finger 6 U

#### for TS-IT

- For U-based cable routing
- Simple, toolless assembly
- Cable routing in conjunction with air baffle plates is supported


#### Material:

- Plastic, UL 94-V0

#### Colour:

- RAL 9005

Packs of	Model No.
14 pc(s).	<b>5502.115</b>

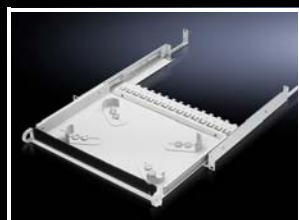

### 482.6 mm (19") drawer

#### to accommodate surplus cables

The 1 U drawer offers a convenient opportunity for storing surplus cables in an organised, compact and secure way within the 482.6 mm (19") levels.

- With brush strip at the front for cable entry
- T-head rail in the rear section for cable clamping
- Ring-shaped kink-free routing of the conductors on adjustable elements in the interior
- May be fitted between two 482.6 mm (19") levels at a distance of 435 – 750 mm
- Independent from the enclosure system
- On both L-shaped and cranked mounting angles and mounting frames

#### Material:

- Sheet steel

#### Colour:

- RAL 7035


#### Supply includes:

- Drawer including telescopic slides and assembly parts

Distance between levels mm	Packs of	Model No.
435 – 750	1 pc(s).	<b>7063.200</b>

#### ⊕ Accessories:

- Nylon loop 7072.220/7072.230, see page 667

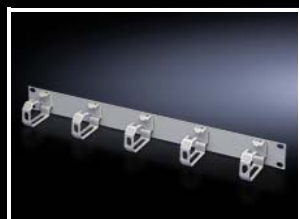

### Cable management panel

#### with plastic rings

For horizontal management of the patch cables, with 5 cable shunting rings. Cable shunting rings supplied loose.

#### Material:

- Panel: Sheet steel
- Rings: Polyamide

#### Colour:

- RAL 7035

U	Ring size mm	Packs of	Model No.
1	70 x 44	1 pc(s).	<b>7159.035</b>



### Cable management panel

#### with steel rings

For horizontal management of the patch cables, with 5 cable shunting rings.

#### Material:

- Panel: Sheet steel
- Rings: Steel

#### Surface finish:

- Rings: Zinc-plated

U	Ring size mm	Colour		Packs of	Model No.
		RAL 7035	RAL 9005		
1	43 x 55	■	–	1 pc(s).	<b>7257.200</b>
1	43 x 55	–	■	1 pc(s).	<b>5502.205</b>
1	43 x 105	■	–	1 pc(s).	<b>7257.035</b>
1	43 x 105	–	■	1 pc(s).	<b>7257.005</b>
2	85 x 125	■	–	1 pc(s).	<b>7257.100</b>
2	85 x 125	–	■	1 pc(s).	<b>7257.105</b>

