


Interior installation

Component shelves for attachment to the 482.6 mm (19") frame

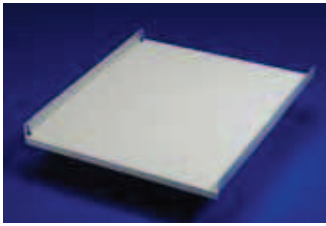

Component shelf, static installation

on the 482.6 mm (19") mounting angles for TE, TS, FR(i)

 

The component shelf is attached directly to the front and rear 482.6 mm (19") mounting angles.

Load capacity:
30 kg surface load, static

Material:
Sheet steel

Colour:
RAL 7035


Supply includes:
Assembly parts.

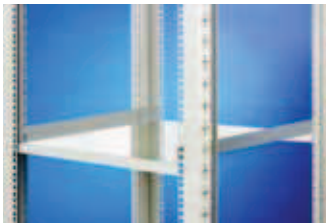

Width mm	Height mm	Depth mm	Distance between 19" levels mm	Model No. DK
511	22	413	495	7000.620

Note:
Not suitable for combination with telescopic slides.

Component shelves for attachment to the 482.6 mm (19") frame

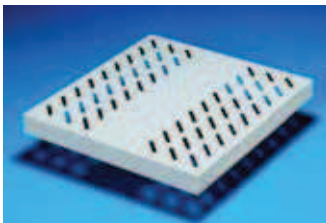

Component shelf, heavy duty

for network enclosures TS with cranked mounting angles

For static installation between two 482.6 mm (19") mounting levels.

The component shelf is located directly onto the cranked mounting angles.

Zinc-plated version:
Load capacity:
75 kg surface load, static

Material:
Sheet steel, zinc-plated, passivated


Supply includes:
Assembly parts.

Spray-finished version:
Load capacity:
100 kg surface load, static

Material:
Sheet steel

Colour:
RAL 7035

Supply includes:
Assembly parts.

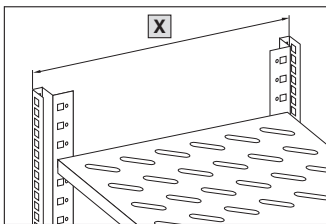

Zinc-plated version:

Dimensions			Distance between levels (X) mm	Model No. DK
Width mm	Height mm	Depth mm		
452.5	20	478	498	7828.950
452.5	20	578	598	7828.960
452.5	20	678	698	7828.970

Spray-finished version:

Dimensions			Distance between levels (X) mm	Model No. DK
Width mm	Height mm	Depth mm		
453	44	470	498	7145.535

Note:
Not suitable for combination with telescopic slides.

Possible alternative:

Component shelf, heavy duty, for 482.6 mm (19") population, may be combined with telescopic slides, see page 1019.