



Central earthing point

For connecting


- Earth straps
- Earthing braids

to the vertical and horizontal enclosure profile. The connection bracket is connected to the enclosure frame with 2 screws and is securely contacted. Earth connection is carried out via the threaded bolt M8 x 20 mm.

Material:
Sheet steel, zinc-plated, passivated.

Packs of	Model No. DK
1	7829.200

Supply includes:
1 connection bracket,
2 screws 5.5 x 13 mm,
2 serrated washers,
1 nut M8,
1 contact washer M8,
1 washer.

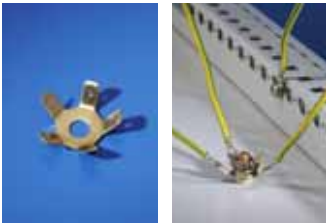

Potential equalisation star for 8 mm earthing bolt

The earthing connector is used for simple potential equalisation on an 8 mm earthing bolt, or in conjunction with central earthing point DK 7829.200. Up to five flat connectors (6.3 mm) may be contacted on one earthing point.

Packs of	Model No. DK
10	7548.210

Supply includes:
10 earthing connectors, including assembly parts.



Complete earthing kit for DK-TS

To DIN EN 60 950/VDE 0805, Ø 4 mm², I_{max}. 40 A. For system-compatible earthing of all enclosure parts on the enclosure frame according to VDE. The earth conductors are pre-assembled ready for connection with connectors and cut to the right length.

Packs of	Model No. DK
1 set	7829.150

Supply includes:
Central earthing point and assembly parts.



Complete earthing kit for TE

To DIN EN 60 950/VDE 0805, Ø 4 mm², I_{max}. 40 A. For system-compatible earthing of all enclosure parts on the enclosure frame according to VDE. The earth conductors are pre-assembled ready for connection with connectors and cut to the right length.

Packs of	Model No. TE
1 set	7000.675

Supply includes:
Assembly parts.



Earthing kit KE

For producing the required external potential equalisation for painted series enclosures

- KL
- AE
- TS

For applications in Unit Group II, Category 3, in compliance with Directive 94/9 EU – Appendix VIII, internal production control.

Packs of	Model No. KE
5	9214.000

Supply includes:
Packs of 5