

Cable management

Gland plates



Plastic cable gland plates

With pre-punched PG holes for cable glands.
Used for sealing standard gland plates.
Temperature range:
suitable for use from -40°C to $+70^{\circ}\text{C}$.


Colour:
RAL 7035

Note:
The applicable size can be taken from the respective product ordering page.


Size	Packs of	Model No. SZ
1	10	2560.000
3	10	2561.000
4	5	2562.000
5	5	2563.000

To order the version with knockouts for metric cable glands, please add extension .010 to the model no.


Size 1

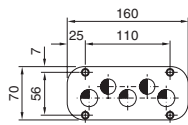


Size 3

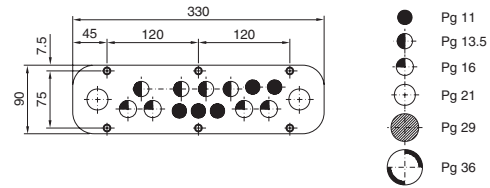

Size 4

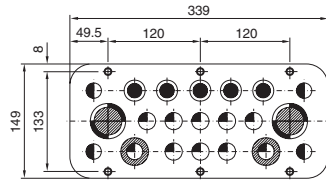

Size 5

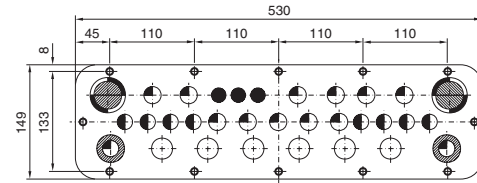

Plastic cable gland plates

With pre-punched PG holes for cable glands.
Used for sealing standard gland plates.
Temperature range:
suitable for use from -40°C to $+70^{\circ}\text{C}$.


Material:
ABS

Colour:
RAL 7035

Note:
The applicable size can be taken from the respective product ordering page.

Size	PG	Qty.	Packs of	Model No. KL
2	13.5	12	5	1581.000
	13.5	6	5	1582.000
	16	2		
	21	2		

KL 1581.000

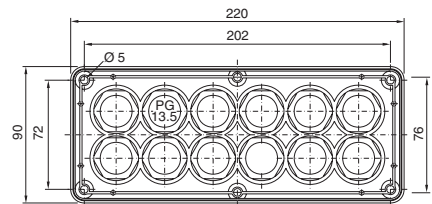

KL 1582.000

