


# Roof/wall mounting

## Roof

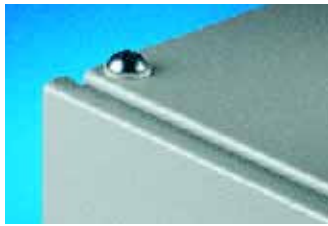

### Roof mounting screw

For screw-fastening the roof plate instead of eye-bolts. With the TS 8, the contact washers for potential equalisation may be taken from the eye-bolts included with the supply of the enclosures.

**Material:**

Sheet steel, zinc-plated, passivated

Packs of	Model No. PS
20	<b>4198.000</b>



### Spacers

**for roof plate TS**

To raise the TS 8 roof for ventilation purposes, in three different heights.

Not suitable for crane transportation!

**Material:**

Hexagonal sectional steel, zinc-plated, passivated

**Supply includes:**

Assembly parts.

Height mm	Packs of	Model No. SZ/DK
10	4	<b>2422.000</b>
20	4	<b>2423.000</b>
50	4	<b>7967.000</b>



### Spacers

**for cover plates TE**

To assist passive ventilation spacers may be used to raise the cover plates.

**Material:**

Hexagonal sectional steel, zinc-plated, passivated

**Supply includes:**

Assembly parts.

Height mm	Packs of	Model No. TE
20	4	<b>7526.963</b>

**Note:**

Spacers are already included with the supply of the TE enclosures.



### Eyebolts

**for TS, ES**

For crane transportation of enclosures, may already be included in the supply.

Thread: M12

Packs of	Model No. PS
4	<b>4568.000</b>



### Eyebolts

**for CM**

For crane transportation of enclosures, with reinforcement plate to be inserted underneath.

Mounting via the two holes in the top of the CM.

Thread: M12

**Supply includes:**

Eyebolts, reinforcement plates.

Packs of	Model No. CM
2	<b>2509.500</b>



### Eyebolts

**for AE**

For crane transportation of enclosures, with reinforcement plate to be inserted underneath.

Thread: M12

**Supply includes:**

Eyebolts, reinforcement plates.

Packs of	Model No. SZ
4	<b>2509.000</b>