

Baying systems TS 8



System accessories Page 507 Baying systems TS 8, sheet steel Page 62 EMC baying systems TS 8 Page 80

Material and surface finish:

- Enclosure frame: Stainless steel 1.4301 (AISI 304), 1.5 mm, uncoated
- Roof: Stainless steel 1.4301 (AISI 304), 1.5 mm, exterior brushed, grain size 400
- Door: Stainless steel 1.4301 (AISI 304), 2 mm, exterior brushed, grain size 400
- Rear panel: Stainless steel 1.4301 (AISI 304), 1.5 mm, exterior brushed, grain size 400
- Gland plates: Stainless steel 1.4301 (AISI 304), 1.5 mm, uncoated
- Mounting plate: Sheet steel, 3 mm, zinc-plated

Protection category IP to IEC 60 529:

- IP 55

Protection category NEMA:

- NEMA 12

Supply includes:

- Enclosure frame with door(s)
- Roof
- Gland plates
- Rear panel
- Mounting plate
- 4 eyebolts
- Lock: 3 mm double-bit

Note:


- Due to the hardness of the material, we recommend using metal multi-tooth screws for the interior installation.

Approvals:

- UL
- CSA
- TÜV
- TÜV Mark
- Germanischer Lloyd
- Russian Maritime Register of Shipping
- Lloyds Register of Shipping
- Bureau Veritas
- VDE

Technical details:

Available on the Internet

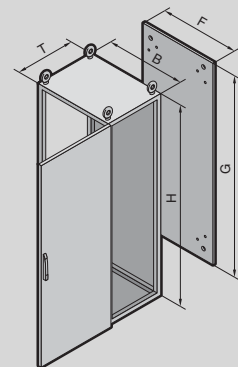

Stainless steel

Width (B) mm	Packs of	800	1200	1200	800	600	800	1200	600	Page
Height (H) mm		1800	1800	1800	1800	1800	2000	2000	2000	
Depth (T) mm		400	400	500	500	500	600	600	600	
Mounting plate width (F) mm		699	1099	1099	699	499	699	1099	499	
Mounting plate height (G) mm		1696	1696	1696	1696	1696	1896	1896	1896	
Model No.	1 pc(s).	8454.600	8456.600	8453.600	8455.600	8457.600	8450.600	8451.600	8452.600	
Door(s)		1	2	2	1	1	1	2	1	
Weight kg		112.9	170.4	174.9	116.3	92.5	129.7	194.7	104.4	
2 support strips fitted in the enclosure depth		–	–	–	–	–	■	■	■	

Accessories

Side panels, screw-fastened, stainless steel	2 pc(s).	8700.840	8700.840	8700.850	8700.850	8700.850	8700.060	8700.060	8700.060	534
Divider panel	1 pc(s).	8609.840	8609.840	8609.850	8609.850	8609.850	8609.060	8609.060	8609.060	537
Divider panel for module plates	1 pc(s).	–	–	8609.100	8609.100	8609.100	8609.130	8609.130	8609.130	538
Base/plinth trim panels, side, 100 mm	1 set(s)	8701.040	8701.040	8701.050	8701.050	8701.050	8701.060	8701.060	8701.060	518
Base/plinth components, front and rear, 100 mm	1 set(s)	8701.800	8701.200	8701.200	8701.800	8701.600	8701.800	8701.200	8701.600	518
Base/plinth trim panels, side, 200 mm	1 set(s)	8702.040	8702.040	8702.050	8702.050	8702.050	8702.060	8702.060	8702.060	518
Base/plinth components, front and rear, 200 mm	1 set(s)	8702.800	8702.200	8702.200	8702.800	8702.600	8702.800	8702.200	8702.600	518
Base/plinth trim, modular	4 pc(s).	2907.000	2907.000	2908.000	2908.000	2908.000	2913.000	2913.000	2913.000	518
Cable clamp rails	2 pc(s).	4192.000	4196.000	4196.000	4192.000	4191.000	4192.000	4196.000	4191.000	665
Sheet steel wiring plan pockets	1 pc(s).	4118.000	4116.000	4116.000	4118.000	4116.000	4118.000	4116.000	4116.000	578
Metal multi-tooth screws	300 pc(s).	2486.300	2486.300	2486.300	2486.300	2486.300	2486.300	2486.300	2486.300	625
System lights		from page	from page	from page	from page	from page	from page	from page	from page	634
Rail systems		from page	from page	from page	from page	from page	from page	from page	from page	605
Levelling feet	4 pc(s).	4612.000	4612.000	4612.000	4612.000	4612.000	4612.000	4612.000	4612.000	521
Baying system		from page	from page	from page	from page	from page	from page	from page	from page	542
Door stay		from page	from page	from page	from page	from page	from page	from page	from page	578
Lock systems		from page	from page	from page	from page	from page	from page	from page	from page	563