

# Base/plinth

## Base/plinth TS

### Cover cap

#### for TS base/plinth components

As a replacement.


#### Material:

- Plastic ABS

#### Colour:

- RAL 9005

For base/plinth height mm	Packs of	Model No.
100	4 pc(s).	<b>8601.130</b>
200	4 pc(s).	<b>8601.140</b>

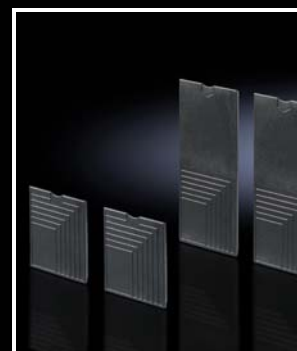

### Base/plinth, stationary

#### for PC, IW

Design-coordinated with the enclosures, height 100 mm, with front projection.

#### Material:

- Sheet steel, 2.0 mm

#### Colour:

- RAL 7035
- Design component, front: RAL 7015

#### Supply includes:

- 1 design component, front
- 1 base/plinth component, rear
- 2 base/plinth trim panels, side

For depth mm	Model No.
600	<b>8800.920</b>



#### Accessories:

- Twin castors 7495.000, see page 522
- Levelling feet 4612.000, see page 521
- Fastening bolt for cable clamp rails 2819.000, see page 516
- Support bracket 4183.000, see page 620



### Filter mat

#### for Flex-Block, vented version

To cover the trim panel in the Flex-Block. The filter mat is simply inserted into the trim panel from the rear. May be shortened to the required length.

For enclosure width mm	Packs of	Model No.
600/800	4 pc(s).	<b>7583.500</b>

