

Baying system

Enclosure suites

Baying attachment, vertical for TS/TS

For baying two populated enclosures on the vertical enclosure section.
Simply locate into the vertical TS punchings, secure and connect both brackets using the hex screws (supplied loose).
Using the fastening bolts, the enclosure is pulled into a defined end position, with a height or side offset of up to ± 2 mm.

Material:

- Sheet steel


Surface finish:

- Zinc-plated

Supply includes:

- Assembly parts

Packs of	Model No.
6 pc(s).	8800.670

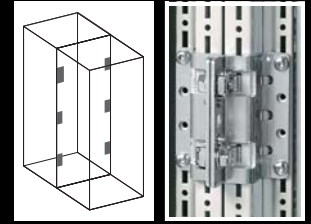

Baying cover, vertical

To balance out the gap between the side panels when baying back-to-back. For enclosure height 2200 mm, or may be cut to length individually for lower heights.

Material:

- Cover section: Plastic

Colour:

- RAL 7035

Supply includes:

- Assembly parts

Packs of	Model No.
2 pc(s).	8800.870



Also required:

- Baying connector, external, 8800.490, see page 544



Baying clamp, horizontal for back-to-back mounting

Two-piece, for in situ assembly of enclosures with mounting plate in the rearmost installation position.

Material:

- Sheet steel

Surface finish:

- Zinc-plated

Supply includes:

- Assembly parts

Packs of	Model No.
4 pc(s).	8800.170

