

Interior installation

Component shelves for frame attachment

Component shelf for frame attachment

Enclosure width 600 and 800 mm for TS and for upgrading existing DK-TS applications

For installation in enclosures **without** 482.6 mm (19") accommodation.

Max. depth of component shelves = Enclosure depth - 100 mm

Technical specifications:

- Mounting bolts or mounting rails may be installed on a 25 mm pitch pattern in the enclosure depth.
- Mounting hole for handles provided.
- Slotted component shelf

Material:


- Sheet steel

Colour:

- RAL 7035

Supply includes:

- Assembly parts

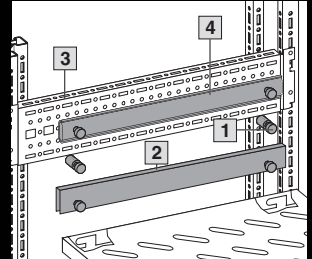

- 1 Fastening bolts
- 2 Mounting rails
- 3 Installation kit
- 4 Telescopic slides

Enclosure width 600 mm

Load capacity kg (surface load, static)	50	50	50	50	100	100	100	100
Component shelf depth mm	400	500	600	700	400	500	600	700
Component shelf height mm	29	29	29	29	45	45	45	45
Model No.	7164.035	7165.035	7166.035	7166.735	7464.035	7465.035	7466.035	7466.735

Enclosure width 800 mm


Load capacity kg (surface load, static)	50	50	50	50	100	100	100	100
Component shelf depth mm	400	500	600	700	400	500	600	700
Component shelf height mm	29	29	29	29	45	45	45	45
Model No.	7184.035	7185.035	7186.035	7186.735	7484.035	7485.035	7486.035	7486.735

! Also required:

TS punched section with mounting flange 17 x 73 mm as installation kit for enclosure depth mm, see page 606	500	8612.050	8612.050	8612.050	8612.050	8612.050	8612.050	8612.050	8612.050
	600	8612.060	8612.060	8612.060	8612.060	8612.060	8612.060	8612.060	8612.060
	800	8612.080	8612.080	8612.080	8612.080	8612.080	8612.080	8612.080	8612.080
	1000	8612.000	8612.000	8612.000	8612.000	8612.000	8612.000	8612.000	8612.000
	1200	8612.020	8612.020	8612.020	8612.020	8612.020	8612.020	8612.020	8612.020

+ Accessories:

Telescopic slides, see page 632	7061.000	7081.000	7161.000	7161.700	7064.000	7065.000	7066.000	7066.700
Handles for component shelves, see page 633	5501.730	5501.730	5501.730	5501.730	5501.730	5501.730	5501.730	5501.730
Hinged cable support	see page 633							

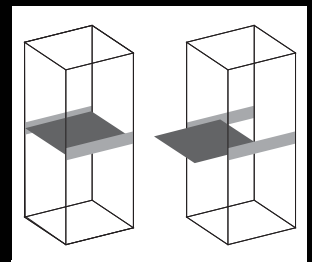

Component shelf, pull-out for TS, PC, IW

For direct mounting on the vertical TS enclosure section.

Load capacity:

- 40 kg surface load, static

Material:

- Sheet steel

Colour:

- RAL 7015

Supply includes:

- 2 telescopic slides.

For enclosures ¹⁾		Support area		Model No.
Width mm	Depth mm	Width mm	Depth mm	
600	600	465	545	6902.960²⁾
600	800	465	745	6902.980

¹⁾ For enclosures without a mounting plate

²⁾ May also be installed in 800 mm deep enclosures based on TS (pull-out rear attachment)

