

# Front assembly



## Front panels for Comfort Panel and Optipanel

**Material:**  
– Aluminium, 3 mm

**Surface finish:**  
– Natural anodised

**Note:**  
– Mounting kits included with the supply of 520 mm wide standard enclosures.

### With mounting hole

Width mm	Height mm	Model No.
482.6 (19')	155.0 (3.5 U)	<b>6027.000</b>
482.6 (19')	310.3 (7 U)	<b>6028.000</b>


### With threaded bolts M5

Width mm	Height mm	Model No.
482.6 (19')	155.0 (3.5 U)	<b>6027.010</b>
482.6 (19')	310.3 (7 U)	<b>6028.010</b>
520	400	<b>6028.014</b>
520	500	<b>6028.015</b>
520	600	<b>6028.016</b>



### Also required:

- Mounting kit for Comfort Panel 6053.800, see page 705
- Mounting kit for Optipanel 6053.000/.500, see page 705

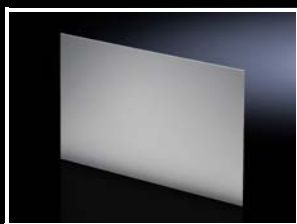

## Front panels for Compact Panel

**Material:**  
– Aluminium, 3 mm

**Surface finish:**  
– Natural anodised

Size W x H mm	To fit Compact Panel	Model No.
178 x 200	6340.000	<b>6028.500</b>
178 x 350	6340.100	<b>6028.510</b>
252 x 200	6340.300	<b>6028.530</b>
252 x 350	6340.400	<b>6028.540</b>



## Cover plate for support arm connection

For secure sealing of an unrequired support arm connection in the enclosure.

**Material:**  
– Sheet steel

**Supply includes:**  
– Seal and assembly parts

**Note:**  
If with  
– Comfort Panel  
– Optipanel  
– Compact Panel  
command panels, there are already 2 support arm cut-outs provided, a cover plate is included with the supply of the enclosure

Support arm connection	Surface finish	Model No.
□ 90 x 71 mm	Spray-finished RAL 7024	<b>6505.200</b>
∅ 130 mm	Zinc-plated, passivated	<b>6505.500</b>
□ 120 x 65 mm	Zinc-plated, passivated	<b>6505.100</b>