
 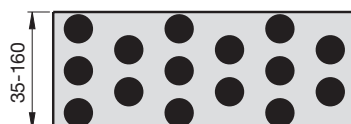

 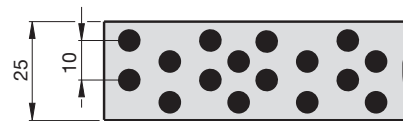



1

### Flachführungsleisten, selbstschmierend

### Flat guide strips, self-lubricating

### Barres de guidage plate, autolubrifiantes


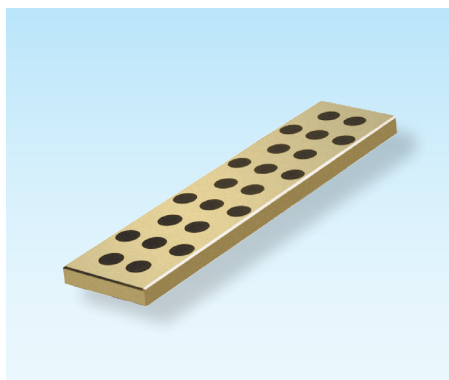


**Z4166-**

Mat.: Bronze  
190-220 HB S10/3000  
< 150 °C



Z4166-B1-H-L1

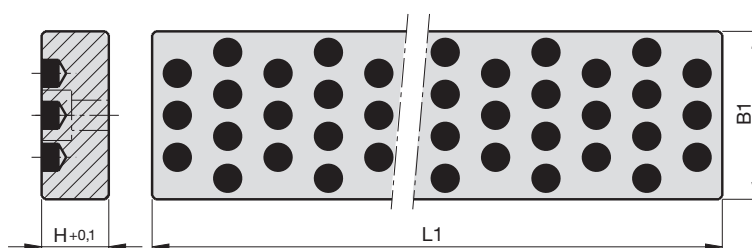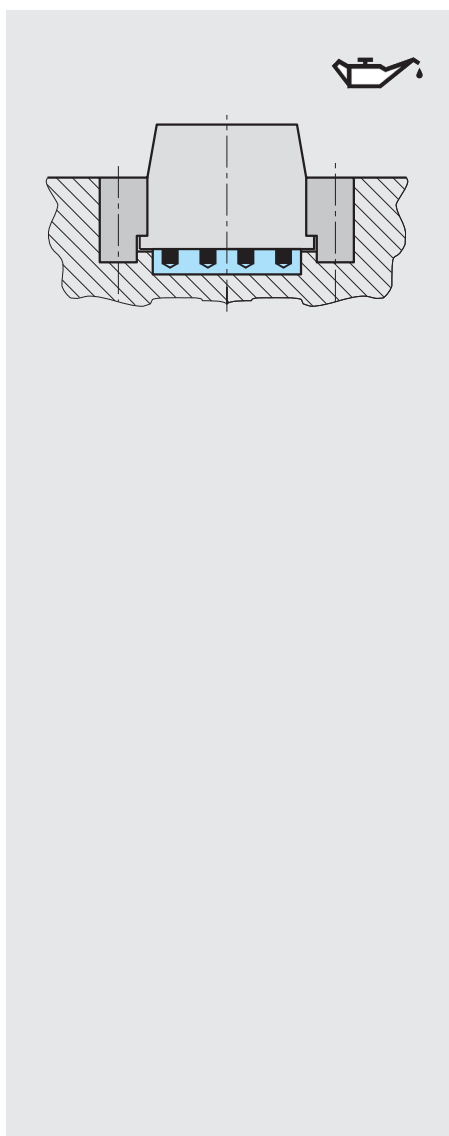

| B1 | H  | L1                   | B1  | H  | L1                   |
|----|----|----------------------|-----|----|----------------------|
| 20 | 4  | 305 <sup>+0,8</sup>  | 60  | 12 | 315 <sup>-2</sup>    |
| 30 | 4  |                      | 80  | 12 | 375 <sup>-2</sup>    |
| 25 | 5  |                      | 40  | 16 | 630 <sup>-2</sup>    |
| 40 | 5  | 605 <sup>+0,8</sup>  | 60  | 16 | 1005 <sup>+0,8</sup> |
| 30 | 6  |                      | 80  | 16 |                      |
| 40 | 6  |                      | 100 | 16 |                      |
| 30 | 8  | 315 <sup>-2</sup>    | 50  | 20 | 1005 <sup>+0,8</sup> |
| 40 | 8  |                      | 80  | 20 |                      |
| 30 | 10 |                      | 100 | 20 |                      |
| 35 | 10 | 375 <sup>-2</sup>    | 125 | 20 | 1005 <sup>+0,8</sup> |
| 40 | 10 | 630 <sup>-2</sup>    | 160 | 20 |                      |
| 50 | 10 | 1005 <sup>+0,8</sup> | 80  | 25 |                      |
| 80 | 10 | 1005 <sup>+0,8</sup> | 100 | 25 | 1005 <sup>+0,8</sup> |
| 30 | 12 |                      | 125 | 25 |                      |
| 40 | 12 |                      | 160 | 25 |                      |
| 50 | 12 |                      |     |    |                      |