
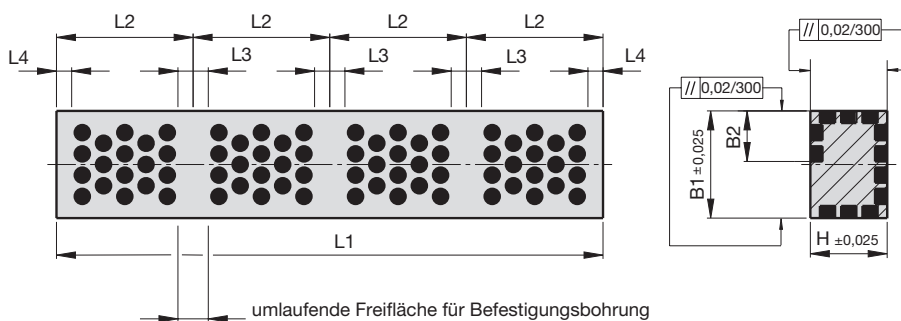


1

Führungsleisten, selbstschmierend

Guide strips, self-lubricating

Barres de guidage, autolubrifiantes

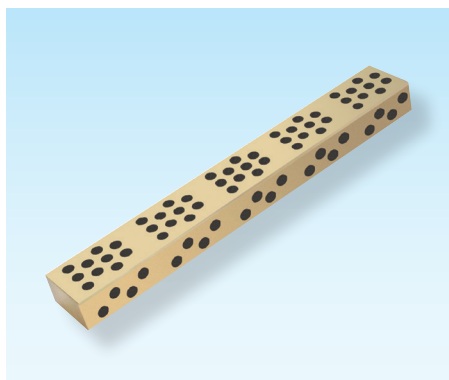

umlaufende Freifläche für Befestigungsbohrung
circulating open space for fixing bores
surface d'incidence tournante pour perçages de fixation

SN4180-

Mat.: Bronze
190-220 HB S10/3000
< 150 °C



SN4180-B1-H-L1



B1	H	L1	B2	L2	L3	L4
25,3	15,3	105	8	35	8	4
	15,3	140	8	35	8	4
	15,3	175	8	35	8	4
	15,3	210	8	35	8	4
	15,3	245	8	35	8	4
	15,3	280	8	35	8	4
	15,3	315	8	35	8	4
	15,3	350	8	35	8	4
	15,3	385	8	35	8	4
	15,3	420	8	35	8	4
	15,3	455	8	35	8	4
35,3	25,3	135	12	45	10	5
	25,3	180	12	45	10	5
	25,3	225	12	45	10	5
	25,3	270	12	45	10	5
	25,3	315	12	45	10	5
	25,3	360	12	45	10	5
	25,3	405	12	45	10	5
	25,3	450	12	45	10	5
45,3	25,3	495	12	45	10	5
	35,3	165	16	55	12	6
	35,3	220	16	55	12	6
	35,3	275	16	55	12	6
	35,3	330	16	55	12	6
	35,3	385	16	55	12	6
	35,3	440	16	55	12	6
	35,3	495	16	55	12	6