


## Schnellkupplungen mit Aussengewinde

## Quick release couplings thread socket

## Raccords rapides avec filetage extérieur

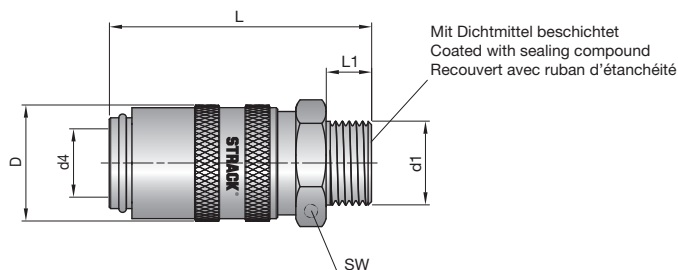

**Z7709-**

Mat.: Ms

Z7709-Type





Type	d1	d4	SW	L	L1	D
5	G 1/4 A	9	17	48	9	18
10	G 3/8 A	9	17	48	9	18
15	G 1/4 A	13,5	22	52	9	23
20	G 3/8 A	13,5	22	52	9	23
25	G 1/2 A	13,5	22	52	10	23

## Umlenkkupplungen

## Diverting sockets

## Douilles de dérivation

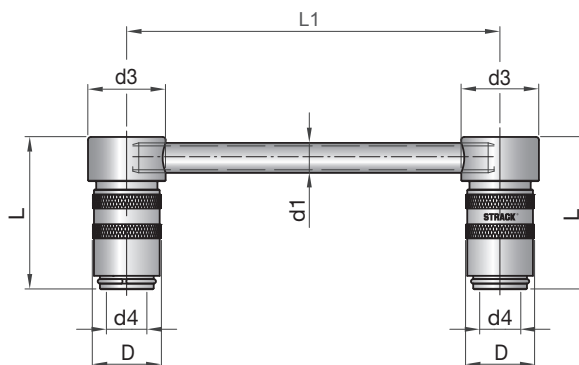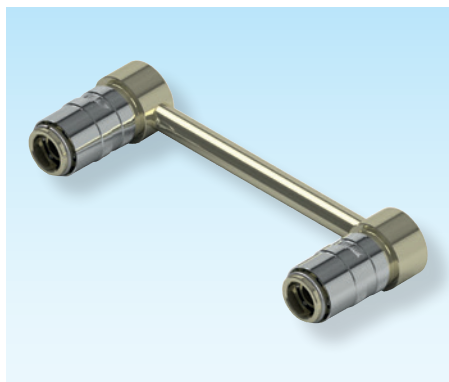

**Z7710-**

Mat.: Ms

Z7710-Type-L1



Type	L1	D	d4	L	d1	d3
5	125	18	9	44	8	20
5	250	18	9	44	8	20
5	500	18	9	44	8	20
15	125	23	13,5	51	10	23
15	250	23	13,5	51	10	23
15	500	23	13,5	51	10	23