


SERIES 67



SOLID HIGH TEMPERATURE THERMOSETTING RESIN WHEELS SWIVEL TOP PLATE BRACKET TYPE "NLX"

Wheel description

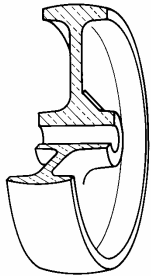


Tread: solid high temperature thermosetting resin wheels, resistant to temperatures from -20°C and +300°C.

Hub: the plain bearing bore results from a hole in the material forming the centre of the wheel and contains the axle.

Bracket description

Standard duty bracket type NLX (max. carrying capacity 400 daN)

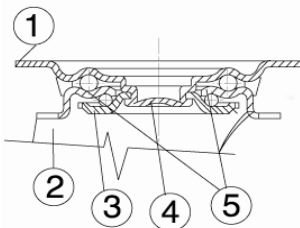

- 1) **Plate:** AISI 304 stainless steel
 - 2) **Fork:** AISI 304 stainless steel
 - 3) **Ball Racing Ring:** AISI 304 stainless steel
 - 4) **King Pin:** incorporated in top plate and cold riveted
 - 5) **Swivel actions:** double ring of greased balls
- Fitting:** top plate

www.tellurerota.com – www.laruotagiusta.it – www.therightwheel.com