


## SERIES 67



### SOLID HIGH TEMPERATURE THERMOSETTING RESIN WHEELS SWIVEL TOP PLATE BRACKET TYPE "PX"

#### Wheel description

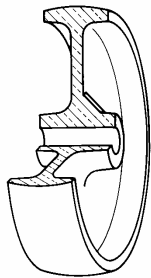


**Tread:** solid high temperature thermosetting resin wheels, resistant to temperatures from -20°C and +300°C.

**Hub:** the plain bearing bore results from a hole in the material forming the centre of the wheel and contains the axle.

#### Bracket description

**Medium-heavy duty bracket type PX (max. carrying capacity 750 daN)**

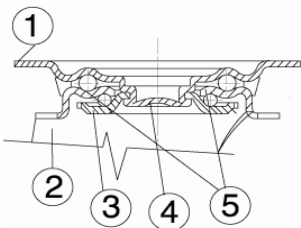

- 1) **Plate:** AISI 304 stainless steel
  - 2) **Fork:** AISI 304 stainless steel
  - 3) **Ball Racing Ring:** AISI 304 stainless steel
  - 4) **King Pin:** A2 stainless steel screw and nut
  - 5) **Swivel actions:** double ring of greased balls
- Fitting:** top plate