


SERIES 62



**“TR-ROLL” POLYURETHANE WHEELS,
ALUMINIUM CENTRE,
SWIVEL TOP PLATE BRACKET TYPE P**

Wheel description

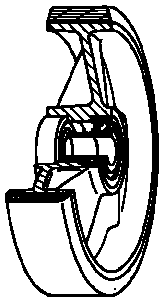


Tread: “TR-ROLL” polyurethane, hardness 75 Shore A.

Centre: aluminium.

Hub: the housing is obtained by moulding and contains ball bearings series Z

Bracket description

Medium-heavy duty bracket type P (max. carrying capacity 750 daN)

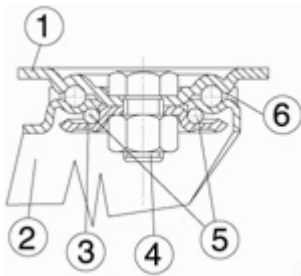

1) **Plate:** electrolytically galvanised steel plate

2) **Fork:** electrolytically galvanised steel plate

3) **Ball Racing Ring:** electrolytically galvanised steel plate

4) **King Pin:** steel screw class 8.8 and nut

5) **Swivel actions:** double ring of greased balls

6) **Dust seal:** red polyamide

Finishing: yellow galvanisation

Fitting: top plate