


SERIES 63



VULKOLLAN® WHEELS, FORGED STEEL CENTRE, SWIVEL TOP PLATE BRACKET TYPE M

Wheel description

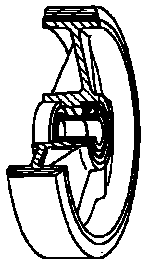


Tread: Vulkollan® polyurethane tread; hardness 93 +/-2 Shore A.

Centre: forged steel.

Hub: the housing is obtained by moulding and turning and contains ball bearings series Z.

Bracket description

Medium duty bracket type M (max. load capacity 500 daN)

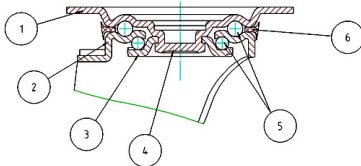

- 1) **Plate:** electrolytically galvanised steel plate
 - 2) **Fork:** electrolytically galvanised steel plate
 - 3) **Ball Racing Ring:** electrolytically galvanised steel plate
 - 4) **King Pin:** incorporated in top plate and cold riveted
 - 5) **Swivel actions:** double ring of greased balls
 - 6) **Dust seal:** blue polyethylene
- Finishing:** electrolytic galvanisation
Fitting: top plate