


SERIES 64



**“TR” POLYURETHANE WHEELS,
CAST IRON CENTRE,
SWIVEL TOP PLATE BRACKET TYPE EEG EHD**

Wheel description

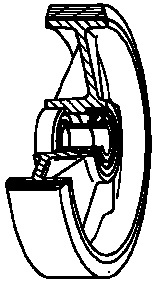


Tread: “TR” polyurethane, hardness 95 +/- 3 Shore A.

Centre: cast iron.

Hub: the housing is obtained by moulding and turning and contains ball bearings series Z

Descrizione supporto

EEG Extra Heavy Duty bracket (max. load capacity 3500 daN)

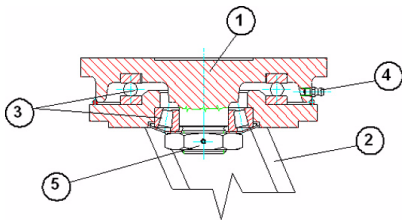

- 1) **Plate:** forged steel with integrated pin
 - 2) **Fork:** drawn sides electrowelded to the flange
 - 3) **Swivel actions:** axial ball bearing and taper roller bearing
 - 4) **Lubricator**
 - 5) **Nut anti-loosening system**
- Finish:** dark green powder coating
Fitting: top plate