


## SERIES 64



**“TR” POLYURETHANE WHEELS,  
CAST IRON CENTRE,  
SWIVEL TOP PLATE BRACKET TYPE EEG MHD**

### Wheel description

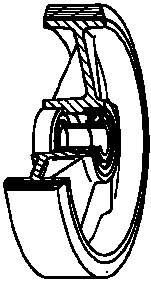


**Tread:** “TR” polyurethane, hardness 95 +/- 3 Shore A.

**Centre:** cast iron.

**Hub:** the housing is obtained by moulding and turning and contains ball bearings series Z

### Bracket description

**EEG Medium Heavy Duty bracket (max. load capacity 900 daN)**

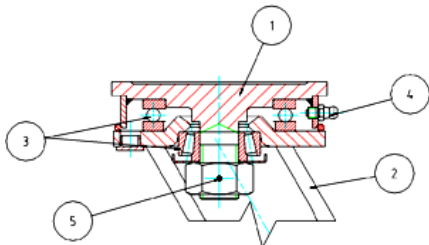

- 1) **Plate:** forged steel with integrated pin
  - 2) **Fork:** drawn sides electrowelded to the flange
  - 3) **Swivel actions:** axial ball bearing and taper roller bearing
  - 4) **Lubricator**
  - 5) **Nut anti-loosening system**
- Finish:** electrolytic galvanisation  
**Fitting:** top plate