


SERIES 64



**“TR” POLYURETHANE WHEELS,
CAST IRON CENTRE,
FIXED BRACKET TYPE NL**

Wheel description

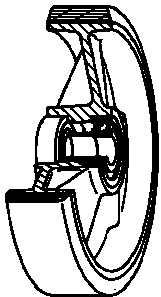


Tread: “TR” polyurethane, hardness 95 +/- 3 Shore A.

Centre: cast iron.

Hub: the housing is obtained by moulding and turning and contains ball bearings series Z

Bracket description

Standard duty bracket type NL (max. load capacity 400 daN)

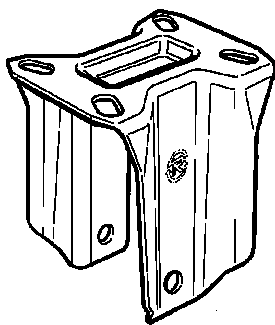

The bracket is made by an electrolytically galvanised steel fork.