


## SERIES 64



**“TR” POLYURETHANE WHEELS,  
CAST IRON CENTRE,  
SWIVEL TOP PLATE BRACKET TYPE NL**

### Wheel description

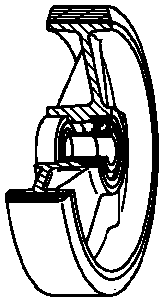


**Tread:** “TR” polyurethane, hardness 95 +/- 3 Shore A.

**Centre:** cast iron.

**Hub:** The housing is obtained by moulding and turning and contains ball bearings series Z

### Bracket description

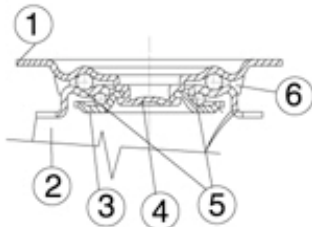

**Standard duty bracket type NL (max. carrying capacity 400 daN)**

1) **Plate:** electrolytically galvanised steel plate

2) **Fork:** electrolytically galvanised steel plate

3) **Ball Racing Ring:** electrolytically galvanised steel plate

4) **King Pin:** incorporated in top plate and cold riveted

5) **Swivel actions:** double ring of greased balls

6) **Dust seal:** orange polyethylene

**Finishing:** electrolytic galvanisation

**Fitting:** top plate