


## SERIES 64



**“TR” POLYURETHANE WHEELS,  
CAST IRON CENTRE,  
FIXED BRACKET TYPE P**

### *Wheel description*

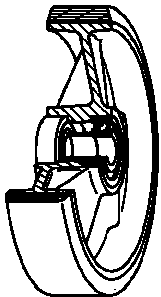


**Tread:** “TR” polyurethane, hardness 95 +/- 3 Shore A.

**Centre:** cast iron.

**Hub:** the housing is obtained by moulding and turning and contains ball bearings series Z

### *Bracket description*

**Medium-heavy duty bracket type P (max. load capacity 750 daN)**

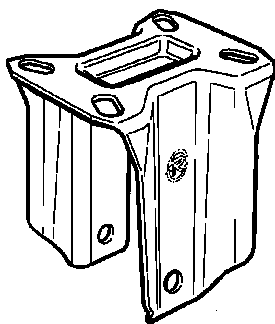

The bracket is made by a yellow galvanised steel fork.