


SERIES 65



**“TR” POLYURETHANE WHEELS,
ALUMINIUM CENTRE,
SWIVEL TOP PLATE BRACKET TYPE “EP”**

Wheel description

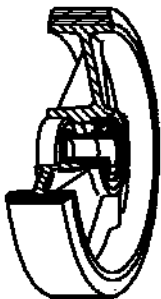


Tread: “TR” polyurethane, hardness 93 +/- 5 Shore A, excellent rolling resistance and elasticity, good resistance to wear and to tearing.

Centre: aluminium.

Hub: the housing is obtained by moulding and contains ball bearings series Z.

Bracket description

Standard duty bracket type EP (max. carrying capacity 1600 daN)

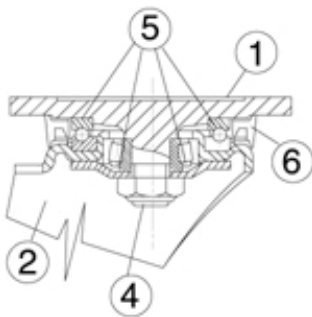

1) **Plate:** green galvanised steel plate

2) **Fork:** green galvanised steel plate

4) **King pin:** solid with the machined plate

5) **Swivel actions:** axial ball bearing anche tapered roller bearing

6) **Dust seal:** orange polyethylene

Finishing: white galvanisation

Fitting: top plate