


SERIES 65



**“TR” POLYURETHANE WHEELS,
CAST IRON CENTRE,
FIXED BRACKET TYPE “NL”**

Wheel description

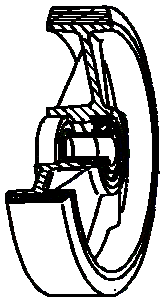


Tread: “TR” polyurethane, hardness 93 +/- 5 Shore A, excellent rolling resistance and elasticity, good resistance to wear and to tearing.

Centre: cast iron.

Hub: the housing is obtained by turning and contains ball bearings series Z.

Bracket description

Standard duty bracket type NL (max. carrying capacity 400 daN)

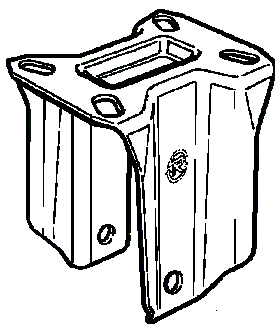

The bracket is made by a galvanised steel fork.