


## SERIES 65HT



**WHEELS IN THICK “TR” POLYURETHANE,  
ALUMINIUM CENTRE,  
SWIVEL TOP PLATE BRACKET TYPE EE MHD**

### Wheel description

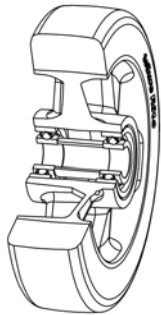


**Tread:** “TR” polyurethane, hardness 95 Shore A, very thick and rounded profile.

**Centre:** aluminium.

**Hub:** the housing is obtained by moulding and contains ball bearings series Z.

### Bracket description

**Bracket EE Medium Heavy Duty max. load capacity 900 daN)**

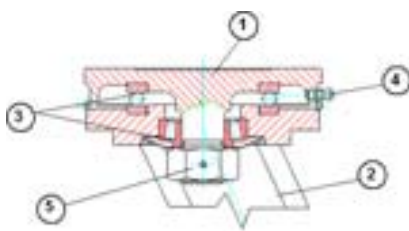

1) **Plate:** forged steel with integrated pin

2) **Fork:** drawn sides electrowelded to the flange

3) **Swivel actions:** axial ball bearing and taper roller bearing

4) **Lubricator**

5) **Nut anti-loosening system**

**Finish:** electrolytic galvanisation

**Fitting:** top plate