


SERIES 72



**SIGMA ELASTIC RUBBER WHEELS
CAST IRON CENTRE
FIXED PLATE BRACKET TYPE EE MHD**

Wheel description

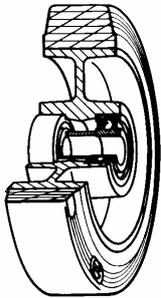


Tread: Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

Centre: cast iron.

Hub: Hub: The housing is obtained by moulding and turning and contains ball bearings series Z.

Bracket description

EE Medium Heavy Duty bracket (max. load capacity 900 daN)

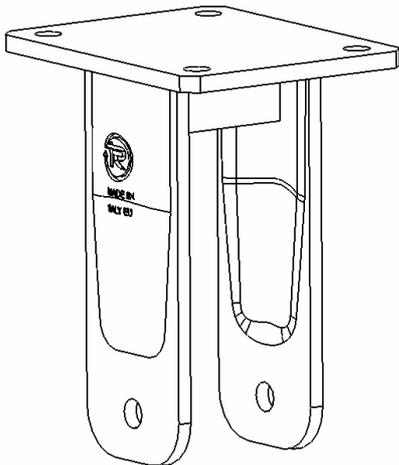

The bracket is made by a steel forged fixing plate with 4 holes, by two steel drawn sides and by a steel central stiffening. These elements are bounded by welding and properly protected against oxydation.