


## SERIES 72



**SIGMA ELASTIC RUBBER WHEELS  
CAST IRON CENTRE  
SWIVEL TOP PLATE BRACKET TYPE EEG HD**

### Wheel description

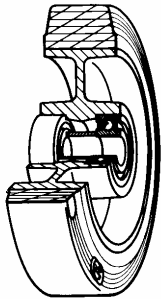


**Tread:** Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

**Centre:** cast iron.

**Hub: Hub:** The housing is obtained by moulding and turning and contains ball bearings series Z.

### Bracket description

**EEG Heavy Duty bracket (max. load capacity 2000 daN)**

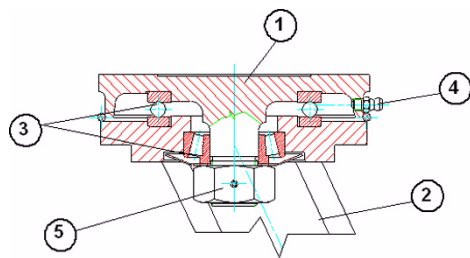

1) **Plate:** forged steel with integrated pin

2) **Fork:** drawn sides electrowelded to the flange

3) **Swivel actions:** axial ball bearing and taper roller bearing

4) **Lubricator**

5) **Nut anti-loosening system**

**Finish:** dark green powder coating

**Fitting:** top plate