


SERIES 72



SIGMA ELASTIC RUBBER WHEELS CAST IRON CENTRE SWIVEL TOP PLATE BRACKET TYPE EP

Wheel description

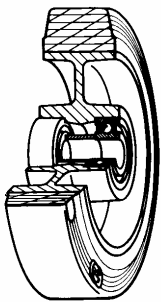


Tread: Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

Centre: cast iron.

Hub: **Hub:** The housing is obtained by moulding and turning and contains ball bearings series Z.

Bracket description

Extra-heavy duty bracket type EP (max. load capacity 1600 daN)

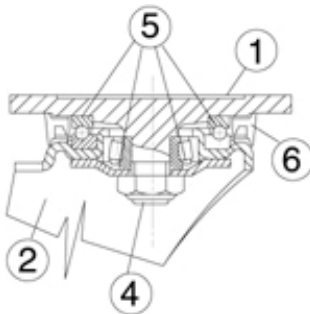

1) **Plate:** electrolytically galvanised forged steel

2) **Fork:** electrolytically galvanised steel plate

4) **Central pin:** solid with the machined plate

5) **Swivel actions:** axial ball bearing and taper roller bearing

6) **Dust seal:** orange polyethylene

Finish: white galvanisation

Fitting top plate