


## SERIES 72



### SIGMA ELASTIC RUBBER WHEELS CAST IRON CENTRE SWIVEL TOP PLATE BRACKET TYPE NL

#### Wheel description

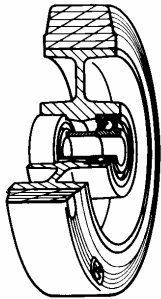


**Tread:** Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

**Centre:** cast iron.

**Hub:** Hub: The housing is obtained by moulding and turning and contains ball bearings series Z.

#### Bracket description

**Standard duty bracket type NL (max. carrying capacity 400 daN)**

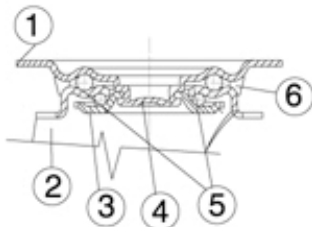

1) **Plate:** electrolytically galvanised steel plate

2) **Fork:** electrolytically galvanised steel plate

3) **Ball Racing Ring:** electrolytically galvanised steel plate

4) **King Pin:** incorporated in top plate and cold riveted

5) **Swivel actions:** double ring of greased balls

6) **Dust seal:** orange polyethylene

**Finishing:** electrolytic galvanisation

**Fitting:** top plate