


## SERIES 72



**SIGMA ELASTIC RUBBER WHEELS  
CAST IRON CENTRE  
FIXED BRACKET TYPE P**

### Wheel description

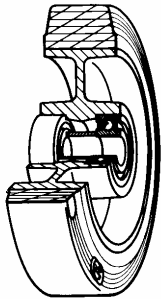


**Tread:** Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

**Centre:** cast iron.

**Hub: Hub:** The housing is obtained by moulding and turning and contains ball bearings series Z.

### Bracket description

**Medium-heavy duty bracket type P (max. load capacity 750 daN)**

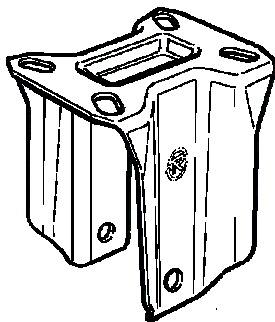

The bracket is made by a yellow galvanised steel fork.