


SERIES 72



**SIGMA ELASTIC RUBBER WHEELS
ALUMINIUM CENTRE
FIXED BRACKET TYPE EEG HD**

Wheel description

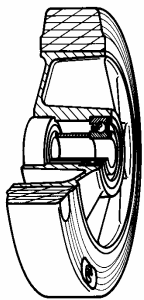


Tread: Sigma Elastic rubber tread; hardness 70 +/-3 Shore A.

Centre: aluminium.

Hub: The housing is obtained by moulding and contains ball bearings series Z.

Bracket description

Heavy Duty bracket type EEG (max. load capacity 2000 daN)

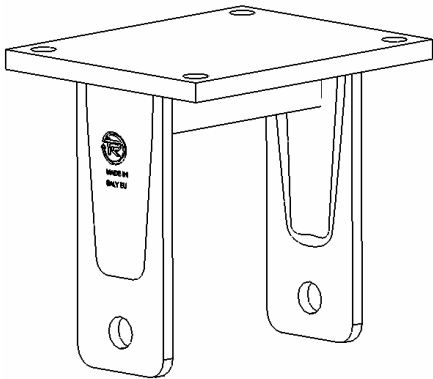

The bracket is made by a steel forged fixing plate with 4 holes, by two steel drawn sides and by a steel central stiffening. These elements are bounded by welding and properly protected against oxydation.